



# SPECIFICATION SHEET

## 16-334



### G-TEK® CR 13 GAUGE POLYKOR™ BLENDED SHELL WITH FOAM NITRILE COATED PALM

- PolyKor™ blended shell is lightweight and provides excellent dexterity, tactile sensitivity and cut resistance
- Seamless construction offers increased comfort and breathability
- Foam Nitrile coated palm and knuckles are compatible with light oils and will provide a good grip and excellent abrasion resistance
- Knit Wrist helps prevent dirt and debris from entering the glove
- Cotton color binding denotes sizing
- Washable, resistant to chemicals, water, and ultraviolet light

#### APPLICATIONS

- Electronics
- Glass cutting
- Sheet metal handling
- Parts assembly
- Sharp small parts handling
- Construction

#### CARE INSTRUCTIONS

Recommend washing gloves in slightly warm water not exceeding 40°C. A mild non-ionic detergent should be used. A 5-10 minute cycle time should be employed. Tumble dry on low - maximum temperature 140°F (60°C)

#### TECHNICAL DATA

MATERIAL	Shell: PolyKor™ / Coating: Nitrile					
COLOR	Shell: ■ Salt & Pepper / Coating: ■ Black					
CUFF STYLE	Continuous Knit					
SIZES	XS - XXL					
PACKAGING	12 pairs per dozen, 6 dozen per case					
CASE	28.3" x 11.8" x 7.9" / 72cm x 30cm x 20cm					
CASE WEIGHT (XS-XXL)	XS	S	M	L	XL	XXL
	8.4 lbs 3.8 kg	88 lbs 4.0 kg	9.5 lbs 4.3 kg	10.9 lbs 4.9 kg	11.9 lbs 5.4 kg	12.8 lbs 5.8 kg
COO	China					



#### DIMENSIONS (in/cm)


	XS	S	M	L	XL	XXL
<b>A</b>	7.7 / 19.5	8.5 / 21.5	9.1 / 23.0	9.6 / 24.5	9.8 / 25.0	10.2 / 26.0
<b>B</b>	3.3 / 8.5	3.5 / 9.0	3.7 / 9.5	3.9 / 10	4.1 / 10.5	4.3 / 11.0
<b>H</b>	■ Purple	■ Red	■ Yellow	■ Brown	■ Black	■ Sky Blue

#### PERFORMANCE PROPERTIES

<b>EN388: 4343</b>	ASTM F2992-15 ANSI Cut Level A2 (Adopted by ANSI/ISEA 02/16) ASTM F1790-05 ANSI Cut Level 2					
ABRASION	0	1	2	3	4	5
CUT	0	1	2	3	4	5
TEAR	0	1	2	3	4	5
PUNCTURE	0	1	2	3	4	5

#### BARCODES

ITEM	BAG	DOZEN	CASE
■ 16-334/XS	616314168376	01616314168375	02616314168374
■ 16-334/S	616314168352	01616314168351	02616314168350
■ 16-334/M	616314168345	01616314168344	02616314168343
■ 16-334/L	616314168338	01616314168337	02616314168336
■ 16-334/XL	616314168369	01616314168368	02616314168367
■ 16-334/XXL	616314168451	01616314168450	02616314168459

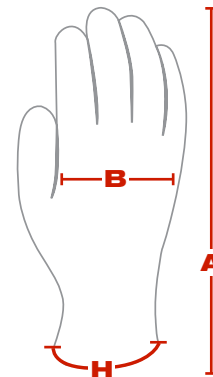

**PROTECTIVE INDUSTRIAL PRODUCTS, INC. | BRINGING THE BEST OF THE WORLD TO YOU®**

AMERICAS: (800) 262-5755 • (518) 861-0133 | EUROPE: +34-96182-41-48 | AMEA: (ASIA, MIDDLE EAST, AFRICA) 852-2475-9228 | [www.pipglobal.com](http://www.pipglobal.com)

This document and the information contained herein is the property of Protective Industrial Products, Inc. (PIP) and may not be used or reproduced without permission. Product users should conduct all appropriate testing or other evaluations to determine the suitability of PIP products for a particular purpose or use within a particular environment. PIP DISCLAIMS ALL WARRANTIES OTHER THAN AS EXPRESSLY PROVIDED.