



SPECIFICATION SHEET

16-343LG



4344

G-TEK® CR 13 GAUGE POLYKOR™ BLENDED SHELL WITH MICROSURFACE NITRILE COATED PALM

- Seamless construction offers increased comfort and breathability
- PolyKor™ shell is lightweight and provides excellent dexterity, tactile sensitivity and cut resistance
- Nitrile micro-surface coated palm helps extend the life of the glove and provide excellent abrasion resistance
- Knit wrist helps prevent dirt and debris from entering the glove
- Cotton color binding denotes sizing
- Washable, resistant to chemicals, water, and ultraviolet light

APPLICATIONS

- Electronics
- Glass cutting
- Sheet metal handling
- General duty
- Parts assembly
- Sharp small parts handling

CARE INSTRUCTIONS

Recommend washing gloves in slightly warm water not exceeding 40°C. A mild non-ionic detergent should be used. A 5-10 minute cycle time should be employed. Tumble dry on low - maximum temperature 140°F (60°C).

TECHNICAL DATA

MATERIAL	Shell: PolyKor™ / Coating: Nitrile					
COLOR	Shell: ■ Hi-Vis Lime / Coating: ■ Black					
CUFF STYLE	Continuous knit					
SIZES	XS - XXL					
PACKAGING	12 pairs per dozen, 6 dozen per case					
CASE DIMENSIONS	11.8" x 5.3" x 5.3" / 30cm x 13.5cm x 13.5cm					
CASE WEIGHT	XS	S	M	L	XL	XXL
	11.7 lbs 5.3 kg	12.3 lbs 5.6 kg	14.3 lbs 6.5 kg	15.4 lbs 7.0 kg	16.5 lbs 7.5 kg	17.6 lbs 8.0 kg
COO	China					

PERFORMANCE PROPERTIES

EN388: 4344 ASTM F2992-15 ANSI Cut Level A2 (Adopted by ANSI/ISEA 02/16)
ASTM F1790-05 ANSI Cut Level 2

ABRASION	0	1	2	3	4	-
CUT	0	1	2	3	4	-
TEAR	0	1	2	3	4	-
PUNCTURE	0	1	2	3	4	-


BARCODES

ITEM	BAG	DOZEN	CASE
■ 16-343LG/XS	616314168505	01616314168504	02616314168503
■ 16-343LG/S	616314168482	01616314168481	02616314168480
■ 16-343LG/M	616314168475	01616314168474	02616314168473
■ 16-343LG/L	616314168468	01616314168467	02616314168466
■ 16-343LG/XL	616314168499	01616314168498	02616314168497
■ 16-343LG/XXL	616314168512	01616314168511	02616314168510



DIMENSIONS (in/cm)

	XS	S	M	L	XL	XXL
A	8.1 / 20.5	8.5 / 21.5	9.1 / 23.0	9.6 / 24.5	10.2 / 26.0	10.6 / 27.0
B	3.5 / 9.0	3.7 / 9.5	3.9 / 10.0	4.1 / 10.5	4.3 / 11.0	4.5 / 11.5
H	■ Purple	■ Red	■ Yellow	■ Brown	■ Black	■ Sky Blue

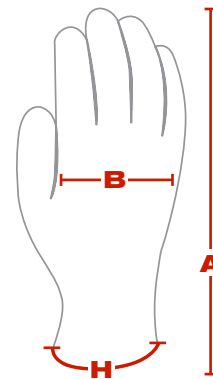

PROTECTIVE INDUSTRIAL PRODUCTS, INC. | BRINGING THE BEST OF THE WORLD TO YOU®

AMERICAS: (800) 262-5755 • (518) 861-0133 | EUROPE: +34-96182-41-48 | AMEA: (ASIA, MIDDLE EAST, AFRICA) 852-2475-9228 | www.pipglobal.com

This document and the information contained herein is the property of Protective Industrial Products, Inc. (PIP) and may not be used or reproduced without permission. Product users should conduct all appropriate testing or other evaluations to determine the suitability of PIP products for a particular purpose or use within a particular environment. PIP DISCLAIMS ALL WARRANTIES OTHER THAN AS EXPRESSLY PROVIDED.