



SPECIFICATION SHEET

16-520HY



4542

G-TEK® POLYKOR™ BLENDED HI-VIS GLOVE WITH POLYURETHANE COATED GRIP – 13 GAUGE

- Seamless construction offers increased comfort and breathability
- PolyKor™ blended shell is lightweight and provides excellent dexterity, tactile sensitivity and cut resistance
- Polyurethane coated palm and fingertips for great abrasion resistance, excellent puncture resistance and outstanding wet/dry grip
- Knit wrist helps prevent dirt and debris from entering the glove
- Hi-Vis coloring makes this product very easy to see
- Cotton color binding denotes sizing
- Washable, resistant to chemicals, water, and ultraviolet light

APPLICATIONS

- Electronics
- Glass cutting
- Sheet metal handling
- General duty
- Parts assembly
- Sharp small parts handling

CARE INSTRUCTIONS

Recommend washing gloves in slightly warm water not exceeding 40°C. A mild non-ionic detergent should be used. A 5-10 minute cycle time should be employed. Tumble dry on low - maximum temperature 140°F (60°C)

TECHNICAL DATA

MATERIAL	PolyKor™ Fiber / Polyurethane					
CONSTRUCTION	Seamless Knit					
COLOR	Hi-Vis Yellow					
CUFF STYLE	Elastic knit					
SIZES	XS - XXL					
PACKAGING	1 pair per bag, 12 pair per dozen, 6 dozen per case					
CASE	14.2" x 11.8" x 12.6" / 36cm x 30cm x 32cm					
CASE WEIGHT (lbs / kg)	XS	S	M	L	XL	XXL
	7.8 / 3.5	7.9 / 3.6	8.4 / 3.8	9.2 / 4.2	10 / 4.5	11.2 / 5
COO	China					

PERFORMANCE PROPERTIES

EN388: 4542	ASTM F2992-15 ANSI Cut Level A3 (Adopted by ANSI/ISEA 02/16)					
ABRASION	0	1	2	3	4	5
CUT	0	1	2	3	4	5
TEAR	0	1	2	3	4	5
PUNCTURE	0	1	2	3	4	5


BARCODES

ITEM	BAG	DOZEN	CASE
16-520HY/XS	616314214554	01616314214553	02616314214552
16-520HY/S	616314214530	01616314214539	02616314214538
16-520HY/M	616314214523	01616314214522	02616314214521
16-520HY/L	616314214516	01616314214515	02616314214514
16-520HY/XL	616314214547	01616314214546	02616314214545
16-520HY/XXL	616314214561	01616314214560	02616314214569



DIMENSIONS (in/cm)

	XS	S	M	L	XL	XXL
A	8.4 / 21.5	8.9 / 22.5	9.3 / 23.5	9.6 / 24.5	10 / 25.5	10.4 / 26.5
B	3.5 / 9	3.7 / 9.5	3.8 / 9.8	3.9 / 10	4.1 / 10.5	4.3 / 11
H	Purple	Red	Yellow	Brown	Black	Sky Blue

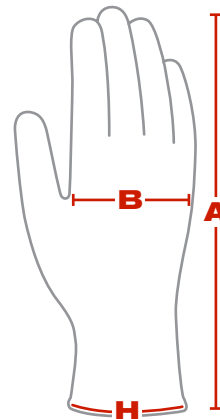

PROTECTIVE INDUSTRIAL PRODUCTS, INC. | BRINGING THE BEST OF THE WORLD TO YOU®

AMERICAS: (800) 262-5755 • (518) 861-0133 | EUROPE: +34-96182-41-48 | AMEA: (ASIA, MIDDLE EAST, AFRICA) 852-2475-9228 | www.pipglobal.com

This document and the information contained herein is the property of Protective Industrial Products, Inc. (PIP) and may not be used or reproduced without permission. Product users should conduct all appropriate testing or other evaluations to determine the suitability of PIP products for a particular purpose or use within a particular environment. PIP DISCLAIMS ALL WARRANTIES OTHER THAN AS EXPRESSLY PROVIDED.