



# SPECIFICATION SHEET

## 16-X310



4544

### G-TEK® POLYKOR™ XRYSTAL™ SEAMLESS KNIT GLOVE WITH NITRILE COATED MICROSURFACE GRIP – 13 GAUGE

- Seamless construction offers increased comfort and breathability
- PolyKor™ Xrystal™ shell is lightweight and provides excellent dexterity, tactile sensitivity and cut resistance
- Nitrile MicroSurface coated palm and fingertips provide a superior grip in dry, wet and oily conditions by reacting like tiny suction cups that attach themselves firmly to the material being handled
- Cotton color binding denotes sizing
- Washable, resistant to chemicals, water, and ultraviolet light
- Compliant with FDA Part 177 - Indirect food activities: Polymers. Subpart C - Substances for use only as components of articles intended for repeated use. Sec. 177.2600

### APPLICATIONS

- Finishing & inspection
- Electronics
- General duty
- Small parts assembly
- Construction
- Maintenance

### CARE INSTRUCTIONS

Machine wash in warm water with detergent. Rinse well and spin extract using high speed. Tumble dry on low to medium heat setting. Can be dry cleaned. Do not bleach.

### TECHNICAL DATA

MATERIAL	PolyKor™ Xrystal™ Engineered Yarn / Nitrile MicroSurface				
COLOR	Shell: ■ Gray / Coating: ■ Black				
CUFF STYLE	Elastic knit				
SIZES	XS - XXL				
PACKAGING	1 pair per bag, 12 pairs per dozen, 6 dozen per case				
CASE DIMENSIONS	16.9" x 12.2" x 9.8" / 43cm x 31cm x 25cm				
CASE WEIGHT	S	M	L	XL	XXL
	7.7 lbs	8.2 lbs	9.6 lbs	9.9 lbs	10.4 lbs
	3.5 kg	3.7 kg	4.2 kg	4.5 kg	4.7 kg
COO	China				

### PERFORMANCE PROPERTIES

EN388: 4544	ASTM F2992-15 ANSI Cut Level A4 (Adopted by ANSI/ISEA 02/16)					
ABRASION	0	1	2	3	4	-
CUT	0	1	2	3	4	5
TEAR	0	1	2	3	4	-
PUNCTURE	0	1	2	3	4	-




### BARCODES

ITEM	BAG	DOZEN	CASE
■ 16-X310/XS	616314214318	01616314214317	02616314214316
■ 16-X310/S	616314214295	01616314214294	02616314214293
■ 16-X310/M	616314214288	01616314214287	02616314214286
■ 16-X310/L	616314214271	01616314214270	02616314214279
■ 16-X310/XL	616314214301	01616314214300	02616314214309
■ 16-X310/XXL	616314214325	01616314214324	02616314214323

### DIMENSIONS (in/cm)

	XS	S	M	L	XL	XXL
A	9.3 / 23.5	9.6 / 24.5	10 / 25.5	10.2 / 26	10.4 / 26.5	10.6 / 26.9
B	3.7 / 9.4	3.9 / 9.8	4 / 10.2	4.2 / 10.6	4.4 / 11.2	4.6 / 11.7
H	■ Purple	■ Red	■ Yellow	■ Brown	■ Black	■ Light Blue

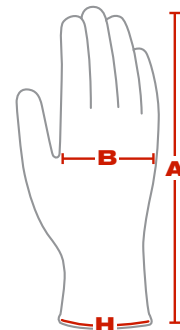

PROTECTIVE INDUSTRIAL PRODUCTS, INC. | BRINGING THE BEST OF THE WORLD TO YOU®

AMERICAS: (800) 262-5755 • (518) 861-0133 | EUROPE: +34-96182-41-48 | AMEA: (ASIA, MIDDLE EAST, AFRICA) 852-2475-9228 | [www.pipglobal.com](http://www.pipglobal.com)

This document and the information contained herein is the property of Protective Industrial Products, Inc. (PIP) and may not be used or reproduced without permission. Product users should conduct all appropriate testing or other evaluations to determine the suitability of PIP products for a particular purpose or use within a particular environment. PIP DISCLAIMS ALL WARRANTIES OTHER THAN AS EXPRESSLY PROVIDED.