



SPECIFICATION SHEET

16-X540



4542

G-TEK® POLYKOR™ XRYSTAL™ SEAMLESS KNIT GLOVE WITH POLYURETHANE COATED SMOOTH GRIP – 13 GAUGE

- Seamless construction offers increased comfort and breathability
- PolyKor™ Xrystal™ shell is lightweight and provides excellent dexterity, tactile sensitivity and cut resistance
- Polyurethane coated palm and fingertips for great abrasion resistance, excellent puncture resistance and outstanding wet/dry grip
- Cotton color binding denotes sizing
- Washable, resistant to chemicals, water, and ultraviolet light
- Compliant with FDA Part 177 - Indirect food activities: Polymers. Subpart C - Substances for use only as components of articles intended for repeated use. Sec. 177.2600

APPLICATIONS

- Finishing & inspection
- Electronics
- General duty
- Small parts assembly
- Construction
- Maintenance

CARE INSTRUCTIONS

Machine wash in warm water with detergent. Rinse well and spin extract using high speed. Tumble dry on low to medium heat setting. Can be dry cleaned. Do not bleach.

TECHNICAL DATA

MATERIAL	PolyKor™ Xrystal™ Engineered Yarn / Polyurethane Coating				
COLOR	Shell: ■ Gray / Coating: ■ Black				
CUFF STYLE	Elastic knit				
SIZES	XS - XXL				
PACKAGING	1 pair per bag, 12 pairs per dozen, 6 dozen per case				
CASE DIMENSIONS	16.9" x 12.2" x 9.8" / 43cm x 31cm x 25cm				
CASE WEIGHT	S	M	L	XL	XXL
	7.7 lbs	8.2 lbs	9.6 lbs	9.9 lbs	10.4 lbs
	3.5 kg	3.7 kg	4.2 kg	4.5 kg	4.7 kg
COO	China				

PERFORMANCE PROPERTIES

EN388: 4542	ASTM F2992-15 ANSI Cut Level A4 (Adopted by ANSI/ISEA 02/16)					
ABRASION	0	1	2	3	4	-
CUT	0	1	2	3	4	5
TEAR	0	1	2	3	4	-
PUNCTURE	0	1	2	3	4	-




BARCODES

ITEM	BAG	DOZEN	CASE
■ 16-X540/XS	616314214493	01616314214492	02616314214491
■ 16-X540/S	616314214479	01616314214478	02616314214477
■ 16-X540/M	616314214462	01616314214461	02616314214460
■ 16-X540/L	616314214455	01616314214454	02616314214453
■ 16-X540/XL	616314214486	01616314214485	02616314214484
■ 16-X540/XXL	616314214509	01616314214508	02616314214507

DIMENSIONS (in/cm)

	XS	S	M	L	XL	XXL
A	8.6 / 22.5	9.3 / 23.5	9.6 / 24.5	9.6 / 25.5	10.4 / 26.5	10.6 / 26.9
B	3.5 / 9	3.7 / 9.5	3.9 / 10	4.2 / 10.6	4.3 / 11	4.5 / 11.4
H	■ Purple	■ Red	■ Yellow	■ Brown	■ Black	■ Light Blue

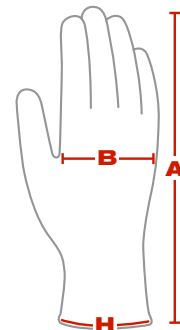

PROTECTIVE INDUSTRIAL PRODUCTS, INC. | BRINGING THE BEST OF THE WORLD TO YOU®

AMERICAS: (800) 262-5755 • (518) 861-0133 | EUROPE: +34-96182-41-48 | AMEA: (ASIA, MIDDLE EAST, AFRICA) 852-2475-9228 | www.pipglobal.com

This document and the information contained herein is the property of Protective Industrial Products, Inc. (PIP) and may not be used or reproduced without permission. Product users should conduct all appropriate testing or other evaluations to determine the suitability of PIP products for a particular purpose or use within a particular environment. PIP DISCLAIMS ALL WARRANTIES OTHER THAN AS EXPRESSLY PROVIDED.