



SPECIFICATION SHEET

16-X570



4542

G-TEK® POLYKOR® XRYSTAL™ SEAMLESS KNIT POLYKOR® XRYSTAL™ BLENDED GLOVE WITH NEOFOAM™ COATED GRIP

- Seamless construction offers increased comfort and breathability
- PolyKor® Xrystal™ shell is lightweight and provides excellent dexterity, tactile sensitivity and cut resistance
- Neofoam™ coated palm and fingertips offers great abrasion resistance and outstanding wet/dry grip
- Knit wrist helps prevent dirt and debris from entering the glove
- Compliant with FDA Part 177 - Indirect food activities: Polymers. Subpart C - Substances for use only as components of articles intended for repeated use. Sec. 177.2600
- Made from component materials that comply with Federal Regulations for food contact 21 CFR, 170-199

APPLICATIONS

- Finishing & inspection
- Electronics
- General duty
- Small parts assembly
- Construction
- Maintenance

CARE INSTRUCTIONS

Recommend washing gloves in slightly warm water not exceeding 40°C. A mild non-ionic detergent should be used. A 5-10 minute cycle time should be employed. Tumble dry on low - maximum temperature 140°F (60°C).

TECHNICAL DATA

MATERIAL	PolyKor® Xrystal™ Engineered Yarn / Neofoam™ Coating					
CONSTRUCTION	Seamless knit					
COLOR	Shell: ■ Gray / Coating: ■ Black					
SIZES	XS - XXL					
PACKAGING	1 pair per bag, 12 pairs per dozen, 6 dozen per case					
CASE DIMENSIONS	15" x 11.8" x 10.6" / 38cm x 30cm x 27cm					
CASE WEIGHT	XS	S	M	L	XL	XXL
	7.5 lbs 3.4 kgs	8 lbs 3.7 kgs	8.8 lbs 4 kgs	10.4 lbs 4.7 kgs	11 lbs 4.9 kgs	11.3 lbs 5.2 kgs
COO	China					

PERFORMANCE PROPERTIES

EN388: 4542	ASTM F2992-15 ANSI Cut Level A4 (Adopted by ANSI/ISEA 02/10)					
ABRASION	0	1	2	3	4	-
CUT	0	1	2	3	4	5
TEAR	0	1	2	3	4	-
PUNCTURE	0	1	2	3	4	-


BARCODES

ITEM	BAG	DOZEN	CASE
■ 16-X570/XS	---	01616314131003	02616314131002
■ 16-X570/S	---	01616314130983	02616314130982
■ 16-X570/M	---	01616314130976	02616314130975
■ 16-X570/L	---	01616314130969	02616314130968
■ 16-X570/XL	---	01616314130990	02616314130999
■ 16-X570/XXL	---	01616314131010	02616314131019



DIMENSIONS (in/cm)

	XS	S	M	L	XL	XXL
A	8.6 / 22	9 / 23	9.4 / 24	9.8 / 25	10.2 / 26	10.6 / 27
B	3.4 / 8.8	3.5 / 9	3.7 / 9.5	4 / 10.3	4.1 / 10.6	4.3 / 10.8
H	■ Purple	■ Red	■ Yellow	■ Brown	■ Black	■ Sky Blue

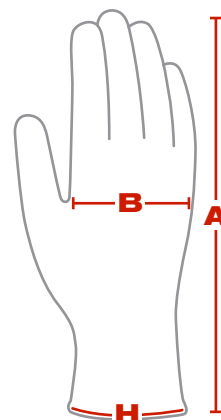

PROTECTIVE INDUSTRIAL PRODUCTS, INC. | BRINGING THE BEST OF THE WORLD TO YOU®

AMERICAS: (800) 262-5755 • (518) 861-0133 | EUROPE: +34-96182-41-48 | AMEA: (ASIA, MIDDLE EAST, AFRICA) 852-2475-9228 | www.pipglobal.com

This document and the information contained herein is the property of Protective Industrial Products, Inc. (PIP) and may not be used or reproduced without permission. Product users should conduct all appropriate testing or other evaluations to determine the suitability of PIP products for a particular purpose or use within a particular environment. PIP DISCLAIMS ALL WARRANTIES OTHER THAN AS EXPRESSLY PROVIDED.