



SPECIFICATION SHEET

18-570



MAXICUT® 3 ENGINEERED YARN GLOVE WITH NITRILE COATED MICRO-FOAM GRIP

- Micro-Foam nitrile coatings are compatible with light oils and will provide a good grip and excellent abrasion resistance
- Unique high performance yarns and fibers that offer cut protection while maintaining high levels of comfort
- Reinforcement between the thumb and forefinger
- Patented micro-foam nitrile coating offers 360° breathability making it the most breathable cut resistant glove on the market
- The Skin Health Alliance has awarded professional dermatological accreditation following review of the scientific dossier behind this product
- 21 CFR Compliant

APPLICATIONS

- Electronics
- Glass cutting
- Metal handling and fabrication
- Food and meat processing

CARE INSTRUCTIONS

Use commercial laundry soap or detergent (do NOT use dry cleaning solutions). Wash in warm to medium hot water, do not exceed 104°F (40°C). Wash for 10 minutes and rinse in cold water. Repeat wash and rinse if soiling is especially heavy. Tumble dry - maximum temperature 140°F (60°C).

TECHNICAL DATA

MATERIAL	Engineered yarn						
COLOR	Green						
CUFF STYLE	Continuous knit						
SIZES	XS - XXXL						
PACKAGING	1 pair per bag, 12 pairs per dozen, 6 dozen per case						
CASE	19.7" x 11.4" x 7.9" / 50cm x 29.5cm x 20cm						
CASE WEIGHT	XS	S	M	L	XL	XXL	XXXL
	8.2 lbs 3.7 kg	9.9 lbs 4.5 kg	10.4 lbs 4.7 kg	11.5 lbs 5.2 kg	12.1 lbs 5.5 kg	13 lbs 5.9 kg	13.9 lbs 6.3 kg
COO	Sri Lanka						

PERFORMANCE PROPERTIES

EN388: 4331	ASTM F2992-15 ANSI Cut Level A2 (Adopted by ANSI/ISEA 02/16) ASTM F1790-05 ANSI Cut Level 2					
ABRASION	0	1	2	3	4	-
CUT	0	1	2	3	4	5
TEAR	0	1	2	3	4	-
PUNCTURE	0	1	2	3	4	-


BARCODES

ITEM	BAG	DOZEN	CASE
18-570/XS	616314044613	01616314044612	02616314044611
18-570/S	616314044618	01616314044618	02616314044618
18-570/M	616314044601	01616314044601	02616314044601
18-570/L	616314044595	01616314044595	02616314044595
18-570/XL	616314044625	01616314044625	02616314044625
18-570/XXL	616314079023	01616314079022	02616314079021
18-570/XXXL	616314120046	01616314120045	02616314120044



DIMENSIONS (in/cm)

	XS	S	M	L	XL	XXL
A	7.9 / 20	8.1 / 20.5	8.7 / 22.0	9.1 / 23.0	9.4 / 24.0	9.6 / 24.5
B	3.2 / 8.5	3.4 / 8.7	3.7 / 9.4	3.9 / 10.4	4.2 / 10.7	4.4 / 11.2
H	Blue	White	Green	Brown	Yellow	Grey

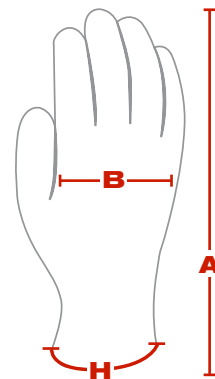

PROTECTIVE INDUSTRIAL PRODUCTS, INC. | BRINGING THE BEST OF THE WORLD TO YOU®

AMERICAS: (800) 262-5755 • (518) 861-0133 | EUROPE: +34-96182-41-48 | AMEA: (ASIA, MIDDLE EAST, AFRICA) 852-2475-9228 | www.pipglobal.com

This document and the information contained herein is the property of Protective Industrial Products, Inc. (PIP) and may not be used or reproduced without permission. Product users should conduct all appropriate testing or other evaluations to determine the suitability of PIP products for a particular purpose or use within a particular environment. PIP DISCLAIMS ALL WARRANTIES OTHER THAN AS EXPRESSLY PROVIDED.