



SPECIFICATION SHEET

18-575



MAXICUT® SEAMLESS KNIT ENGINEERED YARN GLOVE WITH NITRILE COATED MICROFOAM GRIP ON PALM, FINGERS & KNUCKLES

- Micro-Foam nitrile coatings are compatible with light oils and will provide a good grip and excellent abrasion resistance
- Unique high performance yarns and fibers that offer cut protection while maintaining high levels of comfort
- Reinforcement between the thumb and forefinger
- Patented micro-foam nitrile coating offers 360° breathability making it the most breathable cut resistant glove on the market
- The Skin Health Alliance has awarded professional dermatological accreditation following review of the scientific dossier behind this product

APPLICATIONS

- Electronics
- Glass cutting
- Metal handling and fabrication
- Food processing
- Meat processing

CARE INSTRUCTIONS

Use commercial laundry soap or detergent (do NOT use dry cleaning solutions). Wash in warm to medium hot water, do not exceed 104°F (40°C). Wash for 10 minutes and rinse in cold water. Repeat wash and rinse if soiling is especially heavy. Tumble dry - maximum temperature 140°F (60°C).

TECHNICAL DATA

MATERIAL	Engineered Yarn					
COLOR	■ Green					
CUFF STYLE	Continuous knit					
SIZES	XS - XXL					
PACKAGING	1 pair per bag, 12 pairs per dozen, 6 dozen per case					
CASE	19.7" x 11.4" x 7.9" / 50cm x 29.5cm x 20cm					
CASE WEIGHT	XS	S	M	L	XL	XXL
	9.9 lbs 4.5 kg	10.8 lbs 4.9 kg	12.1 lbs 5.5 kg	13.7 lbs 6.2 kg	14.6 lbs 6.6 kg	15.2 lbs 6.9 kg
COO	Sri Lanka					

PERFORMANCE PROPERTIES

EN388: 4331	ASTM F2992-15 ANSI Cut Level A2 (Adopted by ANSI/ISEA 02/16)					
	ASTM F1790-05 ANSI Cut Level 2					
ABRASION	0	1	2	3	4	-
CUT	0	1	2	3	4	5
TEAR	0	1	2	3	4	-
PUNCTURE	0	1	2	3	4	-

BARCODES

ITEM	BAG	DOZEN	CASE
■ 18-575/XS	616314122613	01616314122612	02616314122611
■ 18-575/S	616314120251	01616314120250	02616314120259
■ 18-575/M	616314120244	01616314120243	02616314120242
■ 18-575/L	616314120237	01616314120236	02616314120235




BARCODES CONT.

■ 18-575/XL	616314120268	01616314120267	02616314120266
■ 18-575/XXL	616314120275	01616314120274	02616314120273

DIMENSIONS (in/cm)

	XS	S	M	L	XL	XXL
A	7.9 / 20	8.1 / 20.5	8.7 / 22.0	9.1 / 23.0	9.4 / 24.0	9.6 / 24.5
B	3.2 / 8.5	3.4 / 8.7	3.7 / 9.4	3.9 / 10.4	4.2 / 10.7	4.4 / 11.2
H	■ Blue	□ White	■ Green	■ Brown	■ Yellow	■ Gray

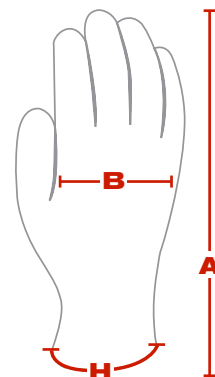

PROTECTIVE INDUSTRIAL PRODUCTS, INC. | BRINGING THE BEST OF THE WORLD TO YOU®

AMERICAS: (800) 262-5755 • (518) 861-0133 | EUROPE: +34-96182-41-48 | AMEA: (ASIA, MIDDLE EAST, AFRICA) 852-2475-9228 | www.pipglobal.com

This document and the information contained herein is the property of Protective Industrial Products, Inc. (PIP) and may not be used or reproduced without permission. Product users should conduct all appropriate testing or other evaluations to determine the suitability of PIP products for a particular purpose or use within a particular environment. PIP DISCLAIMS ALL WARRANTIES OTHER THAN AS EXPRESSLY PROVIDED.