



# SPECIFICATION SHEET

## 19-D324



### G-TEK® 3GX 13 GAUGE DYNEEMA® DIAMOND BLENDED SHELL WITH POLYURETHANE COATED PALM

- Seamless construction offers increased comfort and breathability
- Dyneema® Diamond blended shell is lightweight and provides excellent dexterity, tactile sensitivity and cut resistance
- Polyurethane coated palm for great abrasion resistance, excellent puncture resistance and outstanding wet/dry grip
- Knit wrist helps prevent dirt and debris from entering the glove
- Cotton color binding denotes sizing

### APPLICATIONS

- Electronics
- Glass cutting
- Metal handling
- Parts assembly
- Sharp small parts handling
- Construction and general duty

### CARE INSTRUCTIONS

Recommend washing gloves in slightly warm water not exceeding 40°C. A mild non-ionic detergent should be used. A 5-10 minute cycle time should be employed. Tumble dry on low - maximum temperature 140°F (60°C)


### TECHNICAL DATA

MATERIAL	Shell: Dyneema® Diamond / Coating: Polyurethane					
COLOR	Shell: <input type="checkbox"/> White / Coating: <input checked="" type="checkbox"/> Black					
CUFF STYLE	Continuous Knit					
SIZES	XS - XXL					
PACKAGING	12 pairs per dozen, 6 dozen per case					
CASE	11.8" x 12.6" x 14.2" / 30cm x 32cm x 36cm					
CASE WEIGHT	XS	S	M	L	XL	2XL
	7.9 lbs 3.6 kg	7.9 lbs 3.6 kg	8.8 lbs 4 kg	9 lbs 4.1 kg	9.9 lbs 4.5 kg	10.1 lbs 4.6 kg
COO	China					



### DIMENSIONS (in/cm)

	XS	S	M	L	XL	XXL
<b>A</b>	8.7 / 22	9.1 / 23	9.4 / 23	9.8 / 25	10.2 / 26	10.6 / 27
<b>B</b>	3.3 / 8.5	3.5 / 9	3.7 / 9.5	3.9 / 10	4.1 / 10.5	4.3 / 11
<b>H</b>	<input checked="" type="checkbox"/> Purple	<input checked="" type="checkbox"/> Red	<input checked="" type="checkbox"/> Yellow	<input checked="" type="checkbox"/> Brown	<input checked="" type="checkbox"/> Black	<input checked="" type="checkbox"/> Sky Blue

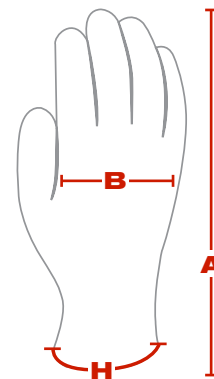

### PERFORMANCE PROPERTIES

<b>EN388: 4542</b>	ASTM F2992-15 ANSI Cut Level A2 (Adopted by ANSI/ISEA 02/16) ASTM F1790-05 ANSI Cut Level 2					
ABRASION	0	1	2	3	4	5
CUT	0	1	2	3	4	5
TEAR	0	1	2	3	4	5
PUNCTURE	0	1	2	3	4	5

### BARCODES

ITEM	PAIR	DOZEN	CASE
<input type="checkbox"/> 19-D324/XS	616314167508	01616314167507	02616314167506
<input type="checkbox"/> 19-D324/S	616314167485	01616314167484	02616314167483
<input type="checkbox"/> 19-D324/M	616314167478	01616314167477	02616314167476
<input type="checkbox"/> 19-D324/L	616314167461	01616314167460	02616314167469
<input type="checkbox"/> 19-D324/XL	616314167492	01616314167491	02616314167490
<input type="checkbox"/> 19-D324/XXL	616314167515	01616314167514	02616314167513

### PROTECTIVE INDUSTRIAL PRODUCTS, INC. | BRINGING THE BEST OF THE WORLD TO YOU®

AMERICAS: (800) 262-5755 • (518) 861-0133 | EUROPE: +34-96182-41-48 | AMEA: (ASIA, MIDDLE EAST, AFRICA) 852-2475-9228 | www.pipglobal.com

This document and the information contained herein is the property of Protective Industrial Products, Inc. (PIP) and may not be used or reproduced without permission. Product users should conduct all appropriate testing or other evaluations to determine the suitability of PIP products for a particular purpose or use within a particular environment. PIP DISCLAIMS ALL WARRANTIES OTHER THAN AS EXPRESSLY PROVIDED.