



SPECIFICATION SHEET

19-D325



G-TEK® 3GX 13 GAUGE DYNEEMA® DIAMOND BLENDED SHELL WITH POLYURETHANE COATED PALM

- Seamless construction offers increased comfort and breathability
- Dyneema® Diamond shell is lightweight and provides excellent dexterity, tactile sensitivity and cut resistance
- Polyurethane coated palm and fingertips for great abrasion resistance, excellent puncture resistance and outstanding wet/dry grip
- Knit wrist helps prevent dirt and debris from entering the glove
- Cotton color binding denotes sizing

APPLICATIONS

- Electronics
- Glass cutting
- Sheet metal handling
- Parts assembly
- Sharp small parts handling
- Construction and general duty

CARE INSTRUCTIONS

Recommend washing gloves in slightly warm water not exceeding 40°C. A mild non-ionic detergent should be used. A 5-10 minute cycle time should be employed. Tumble dry on low - maximum temperature 140°F (60°C)

TECHNICAL DATA

MATERIAL	Shell: Dyneema® Diamond blend / Coating: Polyurethane						
COLOR	Shell: <input type="checkbox"/> White / Coating: <input type="checkbox"/> White						
CUFF STYLE	Continuous Knit						
SIZES	XXS - XXL						
PACKAGING	12 pairs per dozen, 6 dozen per case						
CASE	11.8" x 12.6" x 14.2" / 30cm x 32cm x 36cm						
CASE WEIGHT	XXS	XS	S	M	L	XL	XXL
	8.8 lbs 4.0 kg	9.3 lbs 4.2 kg	9.9 lbs 4.5 kg	10.4 lbs 4.7 kg	11.2 lbs 5.1 kg	11.7 lbs 5.3 kg	12.8 lbs 5.8 kg
COO	China						



DIMENSIONS (in/cm)


	XXS	XS	S	M	L	XL	XXL
A	8.3 / 21.0	8.7 / 22.0	9.1 / 23.0	9.4 / 24.0	9.8 / 25.0	10.2 / 26.0	10.6 / 27.0
B	3.1 / 8.0	3.3 / 9.0	3.5 / 8.5	3.7 / 9.5	3.9 / 10.0	4.1 / 10.5	4.3 / 11.0
H							

PERFORMANCE PROPERTIES

EN388: 4541	ASTM F2992-15 ANSI Cut Level A3 (Adopted by ANSI/ISEA 02/16) ASTM F1790-05 ANSI Cut Level 3					
ABRASION	0	1	2	3	4	5
CUT	0	1	2	3	4	5
TEAR	0	1	2	3	4	5
PUNCTURE	0	1	2	3	4	5

BARCODES

ITEM	PAIR	DOZEN	CASE
<input type="checkbox"/> 19-D325/XXS	616314167645	01616314167644	02616314167643
<input type="checkbox"/> 19-D325/XS	616314167621	01616314167629	02616314167629
<input type="checkbox"/> 19-D325/S	616314167607	01616314167606	02616314167605
<input type="checkbox"/> 19-D325/M	616314167591	01616314167590	02616314167599
<input type="checkbox"/> 19-D325/L	616314167584	01616314167583	02616314167582
<input type="checkbox"/> 19-D325/XL	616314167614	01616314167613	02616314167612
<input type="checkbox"/> 19-D325/XXL	616314167638	01616314167637	02616314167636

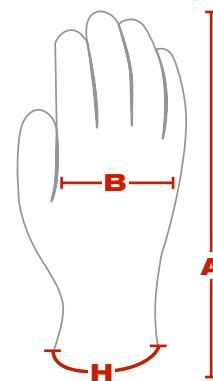

PROTECTIVE INDUSTRIAL PRODUCTS, INC. | BRINGING THE BEST OF THE WORLD TO YOU®

AMERICAS: (800) 262-5755 • (518) 861-0133 | EUROPE: +34-96182-41-48 | AMEA: (ASIA, MIDDLE EAST, AFRICA) 852-2475-9228 | www.pipglobal.com

This document and the information contained herein is the property of Protective Industrial Products, Inc. (PIP) and may not be used or reproduced without permission. Product users should conduct all appropriate testing or other evaluations to determine the suitability of PIP products for a particular purpose or use within a particular environment. PIP DISCLAIMS ALL WARRANTIES OTHER THAN AS EXPRESSLY PROVIDED.