



SPECIFICATION SHEET

19-D327



G-TEK® 3GX 15 GAUGE DYNEEMA® DIAMOND BLENDED SHELL WITH POLYURETHANE COATED PALM

- Seamless construction offers increased comfort and breathability
- Dyneema® Diamond shell is lightweight and provides excellent dexterity, tactile sensitivity and cut resistance
- Polyurethane coated palm and fingertips for great abrasion resistance, excellent puncture resistance and outstanding wet/dry grip
- Knit wrist helps prevent dirt and debris from entering the glove
- Cotton color binding denotes sizing

APPLICATIONS

- Electronics
- Glass cutting
- Sheet metal handling
- Parts assembly
- Sharp small parts handling
- Construction and general duty

CARE INSTRUCTIONS

Recommend washing gloves in slightly warm water not exceeding 40°C. A mild non-ionic detergent should be used. A 5-10 minute cycle time should be employed. Tumble dry on low - maximum temperature 140°F (60°C)

TECHNICAL DATA

MATERIAL	Shell: Dyneema® Diamond blend / Coating: Polyurethane					
COLOR	Shell: ■ Gray / Coating: ■ Gray					
CUFF STYLE	Continuous Knit					
SIZES	XS - XXL					
PACKAGING	12 pairs per dozen, 6 dozen per case					
CASE	11.8" x 12.6" x 14.2" / 30cm x 32cm x 36cm					
CASE WEIGHT	XS	S	M	L	XL	XXL
	9.3 lbs 4.2 kg	9.9 lbs 4.5 kg	10.4 lbs 4.7 kg	11.2 lbs 5.1 kg	11.7 lbs 5.3 kg	12.8 lbs 5.8 kg
COO	China					

PERFORMANCE PROPERTIES

EN388: 4542 ASTM F2992-15 ANSI Cut Level A3 (Adopted by ANSI/ISEA 02/16)
ASTM F1790-05 ANSI Cut Level 3

ABRASION	0	1	2	3	4	5
CUT	0	1	2	3	4	5
TEAR	0	1	2	3	4	5
PUNCTURE	0	1	2	3	4	5


BARCODES

ITEM	PAIR	DOZEN	CASE
■ 19-D327/XS	616314167751	01616314167750	02616314167759
■ 19-D327/S	616314167737	01616314167736	02616314167735
■ 19-D327/M	616314167720	01616314167729	02616314167728
■ 19-D327/L	616314167713	01616314167712	02616314167711
■ 19-D327/XL	616314167744	01616314167743	02616314167742
■ 19-D327/XXL	616314167768	01616314167767	02616314167766



DIMENSIONS (in/cm)

	XS	S	M	L	XL	XXL
A	8.7 / 22.0	9.1 / 23.0	9.4 / 24.0	9.8 / 25.0	10.2 / 26.0	10.6 / 27.0
B	3.5 / 9.0	3.7 / 9.5	3.9 / 9.8	4.0 / 10.1	4.1 / 10.5	4.3 / 11.0
H	■ Purple	■ Red	■ Yellow	■ Brown	■ Black	■ Sky Blue

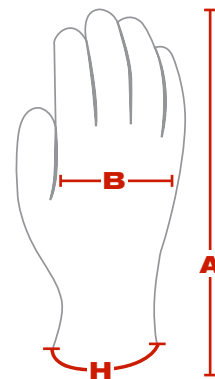

PROTECTIVE INDUSTRIAL PRODUCTS, INC. | BRINGING THE BEST OF THE WORLD TO YOU®

AMERICAS: (800) 262-5755 • (518) 861-0133 | EUROPE: +34-96182-41-48 | AMEA: (ASIA, MIDDLE EAST, AFRICA) 852-2475-9228 | www.pipglobal.com

This document and the information contained herein is the property of Protective Industrial Products, Inc. (PIP) and may not be used or reproduced without permission. Product users should conduct all appropriate testing or other evaluations to determine the suitability of PIP products for a particular purpose or use within a particular environment. PIP DISCLAIMS ALL WARRANTIES OTHER THAN AS EXPRESSLY PROVIDED.