



SPECIFICATION SHEET

19-D340LG



G-TEK® 3GX SEAMLESS KNIT DYNEEMA® DIAMOND SHELL WITH NITRILE COATED FOAM GRIP

- Seamless construction offers increased comfort and breathability
- Dyneema® Diamond shell is lightweight and provides excellent dexterity, tactile sensitivity and cut resistance
- Nitrile coated palm and fingertips for excellent dry grip and will not absorb liquids into the coating
- Knit wrist helps prevent dirt and debris from entering the glove
- Hi-Vis coloring makes this product very easy to see
- Made from component materials which comply with Federal regulations for food contact. 21 CFR, 170-199
- Cotton color binding denotes sizing
- Washable, resistant to chemicals, water, and ultraviolet light

APPLICATIONS

- Electronics
- Glass cutting
- Metal handling
- Construction

CARE INSTRUCTIONS

Recommend washing gloves in slightly warm water not exceeding 40°C. A mild non-ionic detergent should be used. A 5-10 minute cycle time should be employed. Tumble dry on low - maximum temperature 140°F (60°C)

TECHNICAL DATA

MATERIAL	Dyneema® Diamond, Nitrile					
CONSTRUCTION	Seamless Knit					
COLOR	Lime Green & Black					
CUFF STYLE	Knit wrist					
SIZES	XS - XXL					
PACKAGING	1 pair per bag, 12 pair per dozen, 6 dozen per case					
CASE	11.8" x 12.6" x 14.2" / 30cm x 32cm x 36cm					
CASE WEIGHT (lbs / kg)	XS	S	M	L	XL	XXL
	12.8 / 5.8	13.4 / 6.1	13.9 / 6.3	15.2 / 6.9	15.9 / 7.2	16.5 / 7.5
COO	China					

PERFORMANCE PROPERTIES

EN388: 4544 ASTM F2992-15 ANSI Cut Level A4 (Adopted by ANSI/ISEA 02/16)
ASTM F1790-05 ANSI Cut Level 4

ABRASION	0	1	2	3	4	5
CUT	0	1	2	3	4	5
TEAR	0	1	2	3	4	5
PUNCTURE	0	1	2	3	4	5


BARCODES

ITEM	PAIR	DOZEN	CASE
19-D340LG/XS	616314118685	01616314118684	01616314118683
19-D340LG/S	616314118661	01616314118660	01616314118669
19-D340LG/M	616314118654	01616314118653	01616314118652
19-D340LG/L	616314118647	01616314118646	01616314118645
19-D340LG/XL	616314118678	01616314118677	01616314118676
19-D340LG/XXL	616314118692	01616314118691	01616314118690



DIMENSIONS (in/cm)

	XS	S	M	L	XL	XXL
A	8.7 / 22	9.1 / 23	9.4 / 24	9.8 / 25	10.2 / 26	10.6 / 27
B	3.3 / 8.5	3.5 / 9	3.7 / 9.5	3.9 / 10	4.1 / 10.5	4.1 / 10.5
H	Purple	Red	Yellow	Brown	Black	Sky Blue

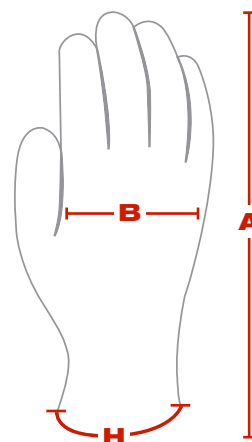

PROTECTIVE INDUSTRIAL PRODUCTS, INC. | BRINGING THE BEST OF THE WORLD TO YOU®

AMERICAS: (800) 262-5755 • (518) 861-0133 | EUROPE: +34-96182-41-48 | AMEA: (ASIA, MIDDLE EAST, AFRICA) 852-2475-9228 | www.pipglobal.com

This document and the information contained herein is the property of Protective Industrial Products, Inc. (PIP) and may not be used or reproduced without permission. Product users should conduct all appropriate testing or other evaluations to determine the suitability of PIP products for a particular purpose or use within a particular environment. PIP DISCLAIMS ALL WARRANTIES OTHER THAN AS EXPRESSLY PROVIDED.