



SPECIFICATION SHEET

19-D360



G-TEK® 3GX 13 GAUGE DYNEEMA® DIAMOND BLENDED SHELL WITH POLYURETHANE COATED PALM

- Seamless construction offers increased comfort and breathability
- Dyneema® Diamond blended shell is lightweight and provides excellent dexterity, tactile sensitivity and cut resistance
- Polyurethane coated palm for great abrasion resistance, excellent puncture resistance and outstanding wet/dry grip
- Washable, resistant to chemicals, water, and ultraviolet light
- Color coded hems for easy size identification
- Knit Wrist helps prevent dirt and debris from entering the glove

APPLICATIONS

- Electronics
- Glass cutting
- Sheet metal handling
- Parts assembly
- Sharp small parts handling
- Construction and general duty

CARE INSTRUCTIONS

Recommend washing gloves in slightly warm water not exceeding 40°C. A mild non-ionic detergent should be used. A 5-10 minute cycle time should be employed. Tumble dry on low - maximum temperature 140°F (60°C)

TECHNICAL DATA

MATERIAL	Shell: Dyneema® Diamond / Coating: Polyurethane			
COLOR	Shell: ■ Gray / Coating: ■ Gray			
CUFF STYLE	Continuous knit			
SIZES	S - XL			
PACKAGING	12 pairs per dozen, 6 dozen per case			
CASE	11.8" x 12.6" x 14.2" / 30cm x 32cm x 36cm			
CASE WEIGHT	S	M	L	XL
	9.3 lbs 4.2 kg	10.6 lbs 4.8 kg	12.1 lbs 5.5 kg	13.0 lbs 5.9 kg
COO	China			

PERFORMANCE PROPERTIES

EN388: 4442 ASTM F2992-15 ANSI Cut Level A3 (Adopted by ANSI/ISEA 02/16)
ASTM F1790-05 ANSI Cut Level 3

ABRASION	0	1	2	3	4	5
CUT	0	1	2	3	4	5
TEAR	0	1	2	3	4	5
PUNCTURE	0	1	2	3	4	5


BARCODES

ITEM	BAG	DOZEN	CASE
■ 19-D360/S	616314167911	01616314167910	02616314167919
■ 19-D360/M	616314167904	01616314167903	02616314167902
■ 19-D360/L	616314167898	01616314167897	02616314167896
■ 19-D360/XL	616314167928	01616314167927	02616314167926



DIMENSIONS (in/cm)

	S	M	L	XL
A	9.1 / 23.0	9.4 / 24.0	9.8 / 25.0	10.2 / 26.0
B	3.7 / 9.4	3.8 / 9.7	4.0 / 10.2	4.1 / 10.5
H	Red	Yellow	Brown	Black

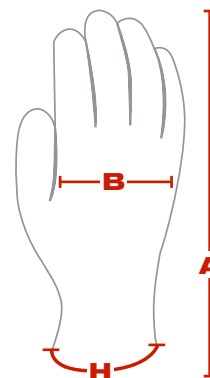

PROTECTIVE INDUSTRIAL PRODUCTS, INC. | BRINGING THE BEST OF THE WORLD TO YOU®

AMERICAS: (800) 262-5755 • (518) 861-0133 | EUROPE: +34-96182-41-48 | AMEA: (ASIA, MIDDLE EAST, AFRICA) 852-2475-9228 | www.pipglobal.com

This document and the information contained herein is the property of Protective Industrial Products, Inc. (PIP) and may not be used or reproduced without permission. Product users should conduct all appropriate testing or other evaluations to determine the suitability of PIP products for a particular purpose or use within a particular environment. PIP DISCLAIMS ALL WARRANTIES OTHER THAN AS EXPRESSLY PROVIDED.