

EVOLUTION™ DELUXE 6151

STANDARD & SHORT BRIM - WHEEL RATCHET

TECHNICAL SPECIFICATION

HEAD PROTECTION

INSTRUCTIONS FOR USE

Fit hard hat on head and ensure the hard hat is adjusted to the size of the user's head. Fasten chin strap (if available) to ensure fit. The harness depth can also be adjusted on this helmet using the unique "3D Adjustment" setting for a precise fit.

SHELL:


High Density
Polyethylene (HDPE)

CHAMLON™ SWEATBAND:

Egyptian cotton core with
porous PU coating for maximum
sweat absorption. PH neutral,
dermatologically tested

WEBBING SUSPENSION:

HDPE Strap & Webbing Clips
with Polyester Webbing Straps

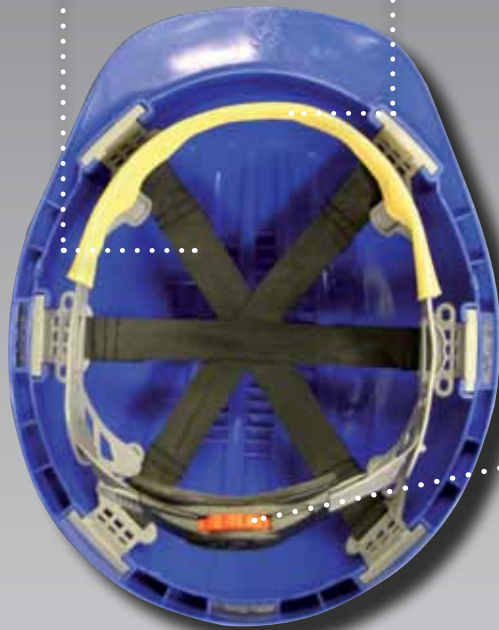

WHEEL RATCHET:

The Revolution™ Wheel Ratchet is the
new easy to use wheel ratchet adjustment
system to create a firm comfort fit with
added security



CLEANING & MAINTENANCE

The shell may be cleaned with soap and warm water and dried with a soft cloth

The hard hat should not be cleaned with chemical or abrasive cleaners

The hard hat should be stored out of direct sunlight

The hard hat should be stored away from chemicals and extremes of temperature

CONFORMITY & TECH DATA

Conforms to ANSI/ISEA Z89.1-2009 Type I Class E (Class C Vented)

Wheel Ratchet for wide size range adjustment - High comfort fit

Suspension can be removed and refitted for reverse wearing

Vented, Non-Vented and Short Brim Options

Custom imprinting is available

COO/Harm Code: UAE / 6506.10.6075

EVOLUTION™ DELUXE 6151

STANDARD & SHORT BRIM - WHEEL RATCHET

TECHNICAL SPECIFICATION

HEAD PROTECTION

DIMENSIONS OF OUTER PACKAGING

Quantity: 10

Weight: 8.4 lbs. (Approx.)



HEIGHT:
18"

LENGTH:
23"

WIDTH:
9.5"

DIMENSIONS OF HARD HAT

Hat Size: 6 5/8" - 8 (20 7/8" - 25")

Weight: 13.2 oz (Approx.)

HARD HAT FEATURES

STANDARDS	ANSI/ISEA Z89.1 - 2009, Type I Class E (Class C Vented)	Yes
PERFORMANCE	Lower Temp (-22° F) Reverse Donning Impact Resistance Electrical Insulation	Yes Yes Yes 54 Joules Yes: Class E 20,000V
SHELL MATERIAL	HDPE Recyclable	Yes Yes
SUSPENSION MATERIAL	HDPE Straps & Clips Polyester Straps	Yes Yes
OPTIONS	Universal Accessories Reflective CR2 option Integrated Eyewear	Yes Yes Yes
SUSPENSION SYSTEM OPTIONS	JSP 3D Wheel Ratchet 6-Point	Yes Yes Yes
CHINSTRAP	4 pts, 2 pts	Yes
LOGO OPTIONS	Front, Rear, Side MOQ Logo	Yes 20

ITEM #	COLOR	BRIM	SHELL	UPC - EACH	UPC - CASE	CASE QTY
280-EV6151-10	White	Standard	Non-Vented	5038428136716	5038428811934	10
280-EV6151-20	Yellow	Standard	Non-Vented	5038428136723	5038428811941	10
280-EV6151-30	Green	Standard	Non-Vented	5038428136730	5038428811958	10
280-EV6151-40	Gray	Standard	Non-Vented	5038428151146	5038428812979	10
280-EV6151-50	Blue	Standard	Non-Vented	5038428136747	5038428811965	10
280-EV6151-60	Red	Standard	Non-Vented	5038428136754	5038428811972	10
280-EV6151-80	Orange	Standard	Non-Vented	5038428136761	5038428811989	10
280-EV6151-LY	Bright Lime/Green	Standard	Non-Vented	5038428136785	5038428812009	10
280-EV6151-OR	Bright Orange	Standard	Non-Vented	5038428136778	5038428811996	10
280-EV6151V-10	White	Standard	Vented	5038428136815	5038428812030	10
280-EV6151V-20	Yellow	Standard	Vented	5038428136822	5038428812047	10
280-EV6151S-10	White	Short	Non-Vented	5038428136853	5038428812078	10
280-EV6151S-20	Yellow	Short	Non-Vented	5038428136860	5038428812085	10
280-EV6151SV-10	White	Short	Vented	5038428136877	5038428812092	10
280-EV6151SV-20	Yellow	Short	Vented	5038428136884	5038428812108	10

LIMITATIONS OF USE: Protection will only be offered if the hard hat is fitted correctly. Any hard hat subjected to severe impact should be replaced immediately. Do not apply paint, solvents or adhesive labels except in accordance with instructions from the manufacturer. The suspension, when in contact with the skin may cause allergic reactions to susceptible individuals. If this occurs leave the hazard area, remove the helmet and seek medical advice. The attention of users is also drawn to the dangers of modifying or removing any of the original component parts, other than as recommended by the manufacturer.