



SPECIFICATION SHEET

280-EV6161

EVOLUTION™ DELUXE 6161 FULL BRIM HARD HAT

- Meets ANSI Z89.1-2009 Type I Class E requirements (Class C for Vented)
- Egyptian cotton core with porous PU coating for maximum sweat absorption. PH neutral, dermatologically tested
- Revolution™ Wheel Ratchet is easy to use and creates a firm comfortable fit
- High-Density Polyethylene (HDPE) shell
- 6-Point suspension system with polyester textile straps offers unrivaled comfort without compromising performance
- Unique "3D Adjustment" provides a precise fit using harness depth settings
- Universal accessory slots
- Vented versions are available to increase air circulation

APPLICATIONS

- Construction
- Oil & gas
- Mining
- Demolition
- High pressure jetting
- Energy companies
- Certain emergency services (FEMA & USAR)
- High-risk environments where high impact situations are of concern

CARE INSTRUCTIONS

The unit may be cleaned with soap and warm water and dried with a soft cloth. The helmet should not be cleaned with chemical or abrasive cleaners. The helmet should be stored out of direct sunlight, away from chemicals and not exposed to extremes of temperature.

TECHNICAL DATA

MATERIAL	Shell: High Density Polyethylene, Recyclable Suspension: HDPE strap & clips, polyester straps Sweatband: Egyptian cotton core with PU coating
COLOR	<div><div>□ White (-10)</div><div>■ Gray (-40)</div><div>■ Lime Yellow (-LY)</div><div>■ Yellow (-20)</div><div>■ Blue (-50)</div><div>■ Green (-30)</div><div>■ Red (-60)</div><div>■ Bright Orange (-OR)</div></div>
HAT SIZE	6 5/8 - 8 (20 7/8" - 25")
EACH WEIGHT	15.2 oz
PACKAGING	10 per case
CASE	12.6" x 21.7" x 17.9" / 32cm x 55.1cm x 45.5cm
CASE WEIGHT	10.5 lbs / 4.8 kg
COO	UAE

BARCODES

ITEM	EACH	DOZEN	CASE
□ 280-EV6161-10	503428010986	---	5038428812535
■ 280-EV6161-20	5038428010993	---	5038428812542
■ 280-EV6161-30	5038428011006	---	5038428812559
■ 280-EV6161-40	5038428173650	---	5038428813594
■ 280-EV6161-50	5038428011013	---	5038428812566
■ 280-EV6161-60	5038428011020	---	5038428812573
■ 280-EV6161-LY	5038428011051	---	5038428812603
■ 280-EV6161-OR	5038428011044	---	5038428812597




BARCODES CONT.

ITEM	EACH	DOZEN	CASE
VENTED HARD HATS (CLASS C)			
□ 280-EV6131V-10	5038428011198	---	5038428812696
■ 280-EV6131V-20	5038428011204	---	5038428812702
■ 280-EV6161V-30	5038428011211	---	5038428812719
■ 280-EV6161V-40	5038428163361	---	5038428813556
■ 280-EV6161V-50	5038428011228	---	5038428812726
■ 280-EV6161V-60	5038428011235	---	5038428812733
■ 280-EV6161V-LY	5038428011266	---	5038428812764
■ 280-EV6161V-OR	5038428011259	---	5038428812757

DIMENSIONS (in)

	OSFA					
A	11.5					
B	6.375					

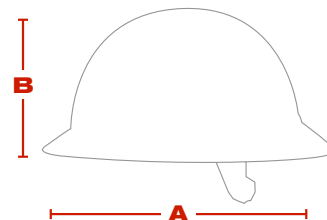

PROTECTIVE INDUSTRIAL PRODUCTS, INC. | BRINGING THE BEST OF THE WORLD TO YOU®

968 Albany Shaker Road | Latham, NY 12110 | 800-262-5755 | 518-861-0133 | Fax: 518-861-0144 | sales@pipusa.com | www.pipusa.com

This document and the information contained herein is the property of Protective Industrial Products, Inc. (PIP) and may not be used or reproduced without permission. Product users should conduct all appropriate testing or other evaluations to determine the suitability of PIP products for a particular purpose or use within a particular environment. PIP DISCLAIMS ALL WARRANTIES OTHER THAN AS EXPRESSLY PROVIDED.