



# SPECIFICATION SHEET

## 300-1500



### NON-ANSI INCIDENT COMMAND VEST

- Non-ANSI incident command vest, 100% polyester solid fabric, hook & loop closure, 4 pockets, 1-inch white reflective prismatic tape.
- Durable polyester solid fabric;
- 1 external upper pocket, 1 internal lower pocket,
- 2 Clear Vinyl Pockets for Laminated Titles:  
Front pocket: 4 1/4"W x 3-1/4"H, Back pocket: 11"W x 4-1/4"H
- 1-inch white reflective tape (except white vest - yellow tape)

### APPLICATIONS

- Easy identification at public events or in emergency situations

### CARE INSTRUCTIONS

Hand wash in cold water. Do not bleach. Air dry.

### TECHNICAL DATA

|              |                                                                                                                                                                                                                                                                     |
|--------------|---------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------|
| MATERIAL     | 100% Polyester                                                                                                                                                                                                                                                      |
| CONSTRUCTION | <b>Main:</b> 235g/m <sup>2</sup> , 100% polyester twill fabric<br><b>Acc:</b> 1-inch reflective tape                                                                                                                                                                |
| COLOR        | <ul style="list-style-type: none"><li>■ Black (300-1502)</li><li>■ Royal Blue (300-1504)</li><li>■ Green (300-1505)</li><li>■ Orange (300-1507)</li><li>■ Red (300-1508)</li><li>■ Yellow (300-1510)</li><li>□ White (300-1511)</li><li>■ Pink (300-1516)</li></ul> |
| SIZES        | M - XL, 2X - 3X                                                                                                                                                                                                                                                     |
| PACKAGING    | 1/Polybag, 25/Case                                                                                                                                                                                                                                                  |
| CASE         | 20.5" x 14.2" x 6.7" / 52cm x 36cm x 17cm                                                                                                                                                                                                                           |
| CASE WEIGHT  | 8.8 lbs / 4.0 kg                                                                                                                                                                                                                                                    |
| COO          | China                                                                                                                                                                                                                                                               |




### DIMENSIONS (in/cm)

|          | M - XL       | 2X - 3X      |  |  |  |
|----------|--------------|--------------|--|--|--|
| <b>A</b> | 39.8 / 101.0 | 42.1 / 107.0 |  |  |  |
| <b>B</b> | 24.0 / 61.0  | 24.8 / 63.0  |  |  |  |

### BARCODES

| ITEM             | BAG            | DOZEN | CASE           |
|------------------|----------------|-------|----------------|
| ■ 300-1500/M-XL  | 01616314090218 | ---   | 02616314090217 |
| ■ 300-1502/2X-3X | 01616314090225 | ---   | 02616314090224 |
| ■ 300-1504/M-XL  | 01616314090232 | ---   | 02616314090231 |
| ■ 300-1504/2X-3X | 01616314090249 | ---   | 02616314090248 |
| ■ 300-1505/M-XL  | 01616314090256 | ---   | 02616314090255 |
| ■ 300-1505/2X-3X | 01616314090263 | ---   | 02616314090262 |
| ■ 300-1507/M-XL  | 01616314090270 | ---   | 02616314090279 |
| ■ 300-1507/2X-3X | 01616314090287 | ---   | 02616314090286 |
| ■ 300-1508/M-XL  | 01616314090294 | ---   | 02616314090293 |
| ■ 300-1508/2X-3X | 01616314090300 | ---   | 02616314090309 |
| ■ 300-1510/M-XL  | 01616314090317 | ---   | 02616314090316 |
| ■ 300-1510/2X-3X | 01616314090324 | ---   | 02616314090323 |
| □ 300-1511/M-XL  | 01616314090331 | ---   | 02616314090330 |
| □ 300-1511/2X-3X | 01616314090348 | ---   | 02616314090347 |
| ■ 300-1516/M-XL  | 01616314162540 | ---   | 02616314162549 |
| ■ 300-1516/2X-3X | 01616314162557 | ---   | 02616314162556 |

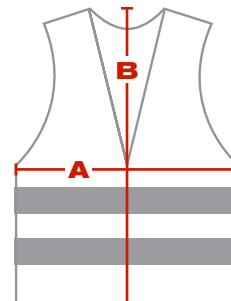

**PROTECTIVE INDUSTRIAL PRODUCTS, INC. | BRINGING THE BEST OF THE WORLD TO YOU®**

968 Albany Shaker Road | Latham, NY 12110 | 800-262-5755 | 518-861-0133 | Fax: 518-861-0144 | sales@pipusa.com | www.pipusa.com

This document and the information contained herein is the property of Protective Industrial Products, Inc. (PIP) and may not be used or reproduced without permission. Product users should conduct all appropriate testing or other evaluations to determine the suitability of PIP products for a particular purpose or use within a particular environment. PIP DISCLAIMS ALL WARRANTIES OTHER THAN AS EXPRESSLY PROVIDED.