



SPECIFICATION SHEET

302-0211



ANSI TYPE R CLASS 2 AND CAN/CSA Z96 X-BACK BREAKAWAY TWO-TONE MESH VEST

- Breathable polyester mesh
- 5 point breakaway
- 2" two-tone reflective tape for optimum visibility
- Hook and loop closure
- 2 external lower flap pockets
- 1 upper chest/radio pocket and 2 mic tabs
- Available in hi-vis lime yellow and hi-vis orange

APPLICATIONS

- Roadway construction workers
- Survey crews
- Utility workers
- Railway and metro workers
- Emergency response personnel

CARE INSTRUCTIONS

Recommend washing in tempered water not exceeding 104°F or 40°C. Wash in a 5-10 minute cycle time or hand wash. Rinse in cold water. Tumble dry at temperature not exceeding 104°F or 40°C, do not wring. Do not wash in biological powder, wash as synthetics. Maximum of 25 wash cycles.

TECHNICAL DATA

MATERIAL	100% Polyester mesh
CONSTRUCTION	120g/m ² polyester mesh, 2" Local TC reflective tape, 1" orange or yellow binding all around, 100% polyester tricot warning tape, 5 breakaway, fastened with hook and loop
COLOR	■ Hi-Vis Yellow ■ Hi-Vis Orange
SIZES	S - 5X
PACKAGING	1/Polybag, 50/Case
CASE	19" x 18" x 10" / 48.3cm x 45.7cm x 25.4cm
CASE WEIGHT	32 lbs / 14.5 kg
COO	China




DIMENSIONS (in/cm)

	S	M	L	XL	2X	3X	4X	5X
A	45/114	47.2/120	49.6/126	52/132	54.3/138	56.7/144	59/150	61.4/156
B	27/69	27/68.6	28/71	28/71	29/73.7	29/73.7	30/76.2	30/76.2

BARCODES

ITEM	BAG	DOZEN	CASE
■ 302-0211-LY/S	616314204807	01616314204806	02616314204805
■ 302-0211-LY/M	616314096433	01616314096432	02616314096431
■ 302-0211-LY/L	616314096105	01616314096104	02616314096103
■ 302-0211-LY/XL	616314096440	01616314096449	02616314096448
■ 302-0211-LY/2X	616314096457	01616314096456	02616314096455
■ 302-0211-LY/3X	616314096464	01616314096463	02616314096462
■ 302-0211-LY/4X	616314096471	01616314096470	02616314096479
■ 302-0211-LY/5X	616314096488	01616314096487	02616314096486
■ 302-0211-OR/S	616314204814	01616314204813	02616314204812
■ 302-0211-OR/M	616314116155	01616314116154	02616314116153
■ 302-0211-OR/L	616314116148	01616314116147	02616314116146
■ 302-0211-OR/XL	616314116162	01616314116161	02616314116160
■ 302-0211-OR/2X	616314116179	01616314116178	02616314116177
■ 302-0211-OR/3X	616314116186	01616314116185	02616314116184
■ 302-0211-OR/4X	616314116193	01616314116192	02616314116191
■ 302-0211-OR/5X	616314116209	01616314116208	02616314116207

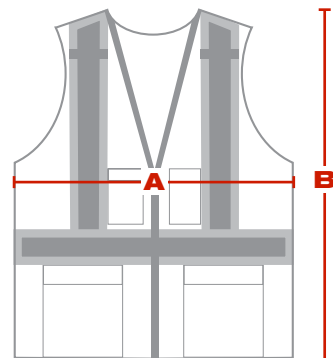

PROTECTIVE INDUSTRIAL PRODUCTS, INC. | BRINGING THE BEST OF THE WORLD TO YOU®

AMERICAS: (800) 262-5755 • (518) 861-0133 | EUROPE: +34-96182-41-48 | AMEA: (ASIA, MIDDLE EAST, AFRICA) 852-2475-9228 | www.pipglobal.com

This document and the information contained herein is the property of Protective Industrial Products, Inc. (PIP) and may not be used or reproduced without permission. Product users should conduct all appropriate testing or other evaluations to determine the suitability of PIP products for a particular purpose or use within a particular environment. PIP DISCLAIMS ALL WARRANTIES OTHER THAN AS EXPRESSLY PROVIDED.