



# SPECIFICATION SHEET

## 302-0702



### ANSI TYPE R CLASS 2 TWO POCKET VALUE MESH VEST

- Breathable polyester mesh
- Hook and loop closure
- 2" silver reflective tape
- 1 internal lower pocket
- 1 external chest pocket

#### APPLICATIONS

- Roadway construction workers
- Survey crews
- Utility workers
- Railway and metro workers
- Emergency response personnel

#### CARE INSTRUCTIONS

Machine wash, 104° F max, 30 cycles. Always wear fastened. The High Visibility properties of this garment must be kept clean to be effective. If faded or permanently soiled it must be replaced with a new one.

#### TECHNICAL DATA

|              |                                                                                                                                                        |
|--------------|--------------------------------------------------------------------------------------------------------------------------------------------------------|
| MATERIAL     | 100% Polyester mesh                                                                                                                                    |
| CONSTRUCTION | <b>Main:</b> 120g/m <sup>2</sup> 100% polyester 5*1 mesh fabric, lime yellow/orange.<br><b>Acc:</b> Local Nylon reflective tape, hook and loop closure |
| COLOR        | <span style="color: yellow;">■</span> Hi-Vis Lime Yellow<br><span style="color: orange;">■</span> Hi-Vis Orange                                        |
| SIZES        | S - 5X                                                                                                                                                 |
| PACKAGING    | 1/Polybag, 50/Case                                                                                                                                     |
| CASE         | 18.9" x 11" x 11.8" / 48cm x 28cm x 30cm                                                                                                               |
| CASE WEIGHT  | 21 lbs / 9.5 kg                                                                                                                                        |
| COO          | China                                                                                                                                                  |


#### BARCODES

| ITEM                                                 | BAG            | DOZEN | CASE           |
|------------------------------------------------------|----------------|-------|----------------|
| <span style="color: yellow;">■</span> 302-0702-LY/S  | 01616314204622 | ---   | 02616314204621 |
| <span style="color: yellow;">■</span> 302-0702-LY/M  | 01616314100306 | ---   | 02616314100305 |
| <span style="color: yellow;">■</span> 302-0702-LY/L  | 01616314100290 | ---   | 02616314100299 |
| <span style="color: yellow;">■</span> 302-0702-LY/XL | 01616314100313 | ---   | 02616314100312 |
| <span style="color: yellow;">■</span> 302-0702-LY/2X | 01616314100320 | ---   | 02616314100329 |
| <span style="color: yellow;">■</span> 302-0702-LY/3X | 01616314100337 | ---   | 02616314100336 |
| <span style="color: yellow;">■</span> 302-0702-LY/4X | 01616314100344 | ---   | 02616314100343 |
| <span style="color: yellow;">■</span> 302-0702-LY/5X | 01616314100351 | ---   | 02616314100350 |
| <span style="color: orange;">■</span> 302-0702-OR/S  | 01616314204639 | ---   | 02616314204638 |
| <span style="color: orange;">■</span> 302-0702-OR/M  | 01616314100375 | ---   | 02616314100374 |
| <span style="color: orange;">■</span> 302-0702-OR/L  | 01616314100368 | ---   | 02616314100367 |
| <span style="color: orange;">■</span> 302-0702-OR/XL | 01616314100382 | ---   | 02616314100381 |
| <span style="color: orange;">■</span> 302-0702-OR/2X | 01616314100399 | ---   | 02616314100398 |
| <span style="color: orange;">■</span> 302-0702-OR/3X | 01616314100405 | ---   | 02616314100404 |
| <span style="color: orange;">■</span> 302-0702-OR/4X | 01616314100412 | ---   | 02616314100411 |
| <span style="color: orange;">■</span> 302-0702-OR/5X | 01616314100429 | ---   | 02616314100428 |



#### DIMENSIONS (in/cm)

|          | S      | M        | L        | XL      | 2X       | 3X       | 4X     | 5X       |
|----------|--------|----------|----------|---------|----------|----------|--------|----------|
| <b>A</b> | 45/114 | 47.2/120 | 49.5/126 | 52/132  | 54.5/138 | 56.5/144 | 59/150 | 61.5/156 |
| <b>B</b> | 24/69  | 28/71.1  | 28/71.1  | 28/71.1 | 29/73.5  | 29/73.5  | 30/76  | 30/76    |

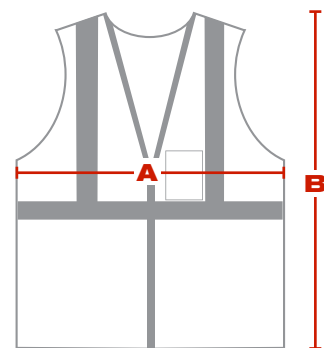

**PROTECTIVE INDUSTRIAL PRODUCTS, INC. | BRINGING THE BEST OF THE WORLD TO YOU®**

AMERICAS: (800) 262-5755 • (518) 861-0133 | EUROPE: +34-96182-41-48 | AMEA: (ASIA, MIDDLE EAST, AFRICA) 852-2475-9228 | [www.pipglobal.com](http://www.pipglobal.com)

This document and the information contained herein is the property of Protective Industrial Products, Inc. (PIP) and may not be used or reproduced without permission. Product users should conduct all appropriate testing or other evaluations to determine the suitability of PIP products for a particular purpose or use within a particular environment. PIP DISCLAIMS ALL WARRANTIES OTHER THAN AS EXPRESSLY PROVIDED.