



SPECIFICATION SHEET

333-1762



ANSI TYPE R CLASS 3 VALUE BOMBER JACKET WITH ZIP-OUT FLEECE LINER

- Durable waterproof polyester outer shell with taped seams
- Removable black fleece liner
- Black knit waist band, cuff and collar
- 2" silver reflective tape
- Adjustable, detachable hideaway hood
- 2 mic tabs, 5 pockets with radio and 2 pen pockets on sleeve

APPLICATIONS

- Roadway construction workers
- Survey crews
- Utility workers
- Railway & metro workers
- Emergency response personnel

CARE INSTRUCTIONS

Machine wash cold. No bleach. Tumble dry low. Do not dry clean.
Do not iron. This garment may be washed up to 25 cycles.

TECHNICAL DATA

MATERIAL	100% Polyester
CONSTRUCTION	Main: 100% polyester 300D Oxford with PU coating, lime yellow/orange. Lining: 280g/100% polyester fleece, detachable, 100% polyester taffeta 190T, lime yellow/orange. Acc: Local nylon reflective tape, resin left insert zipper, gray ribbon tape on each shoulder tape.
COLOR	■ Hi-Vis Lime Yellow or ■ Hi-Vis Orange
SIZES	S - 5X
PACKAGING	1 per polybag, 10 per case
CASE DIMENSIONS	24" x 16.5" x 8" / 62cm x 42cm x 20cm
CASE WEIGHT	33 lbs / 15 kg
COO	China


BARCODES

ITEM	BAG	DOZEN	CASE
■ 333-1762-LY/S	616314190438	---	02616314190436
■ 333-1762-LY/M	616314110061	---	02616314110069
■ 333-1762-LY/L	616314110054	---	02616314110052
■ 333-1762-LY/XL	616314110078	---	02616314110076
■ 333-1762-LY/2X	616314110085	---	02616314110083
■ 333-1762-LY/3X	616314110092	---	02616314110090
■ 333-1762-LY/4X	616314110108	---	02616314110106
■ 333-1762-LY/5X	616314110115	---	02616314110113
■ 333-1762-OR/S	616314190445	---	02616314190443
■ 333-1762-OR/M	616314117442	---	02616314117440
■ 333-1762-OR/L	616314117435	---	02616314117433
■ 333-1762-OR/XL	616314117459	---	02616314117457
■ 333-1762-OR/2X	616314117466	---	02616314117464
■ 333-1762-OR/3X	616314117473	---	02616314117471
■ 333-1762-OR/4X	616314117480	---	02616314117488
■ 333-1762-OR/5X	616314117497	---	02616314117495



DIMENSIONS (in/cm)

	S	M	L	XL	2X	3X	4X	5X
A	52 / 132	54 / 137	56 / 142	59 / 150	63 / 160	66 / 167.6	70 / 177.8	74 / 188
B	30.5 / 77.5	31 / 78.7	31.5 / 80	31.5 / 80	32 / 81.3	32.5 / 82.6	33 / 83.8	33.5 / 85.1
C	12.5 / 31.8	12.5 / 31.8	13 / 33	13.3 / 33.8	13.7 / 34.8	14 / 35.6	14.5 / 36.8	15 / 38
D	25.5 / 64.8	26 / 66	26.5 / 67.3	27 / 68.6	27.5 / 69.9	28 / 71	28.5 / 72.4	29 / 73.7

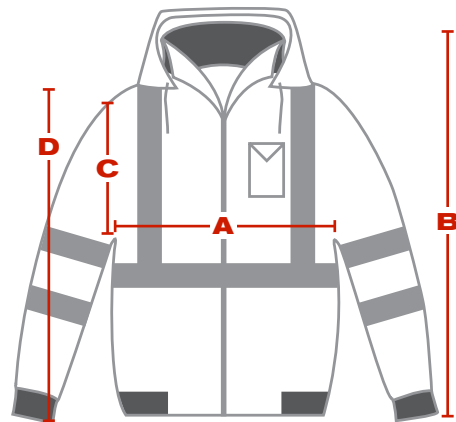

PROTECTIVE INDUSTRIAL PRODUCTS, INC. | BRINGING THE BEST OF THE WORLD TO YOU®

AMERICAS: (800) 262-5755 • (518) 861-0133 | EUROPE: +34-96182-41-48 | AMEA: (ASIA, MIDDLE EAST, AFRICA) 852-2475-9228 | www.pipglobal.com

This document and the information contained herein is the property of Protective Industrial Products, Inc. (PIP) and may not be used or reproduced without permission. Product users should conduct all appropriate testing or other evaluations to determine the suitability of PIP products for a particular purpose or use within a particular environment. PIP DISCLAIMS ALL WARRANTIES OTHER THAN AS EXPRESSLY PROVIDED.