



SPECIFICATION SHEET

333-1770



ANSI TYPE R CLASS 3 RIPSTOP PREMIUM PLUS BOMBER JACKET WITH ZIP-OUT FLEECE LINER

- Ripstop polyester 300D coated waterproof outer shell with taped seams
- Double front storm flap zipper closure
- Removable black 280g fleece liner
- Water tight "D" ring access
- I.D. pocket and radio/cell pocket
- Adjustable, detachable hideaway hood, elastic cuffs, and elastic waist
- 2 mic tabs, inner liner pockets for keeping items out of the elements
- 2 pen pockets on sleeve

APPLICATIONS

- Roadway construction workers
- Survey crews
- Utility workers
- Railway & metro workers
- Emergency response personnel

CARE INSTRUCTIONS

Machine wash cold. No bleach. Tumble dry low. Do not dry clean. Do not iron. This garment may be washed up to 25 cycles.

TECHNICAL DATA

MATERIAL	100% Polyester
CONSTRUCTION	Main: 100% polyester 300D Oxford with PU coating, rip-stop, non-breathable lime yellow/orange. Lining: 280g/m2 100% polyester fleece, detachable, 100% polyester taffeta 190T, lime yellow/orange. Acc: Local nylon reflective tape, #8 resin left insert zipper.
COLOR	■ Hi-Vis Lime Yellow or ■ Hi-Vis Orange
SIZES	S - 5X
PACKAGING	1 per polybag, 10 per case
CASE DIMENSIONS	24" x 16.5" x 16.1" / 62cm x 42cm x 41cm
CASE WEIGHT	33 lbs / 15 kg
COO	China




DIMENSIONS (in/cm)

	S	M	L	XL	2X	3X	4X	5X
A	52 / 132	54 / 137	56 / 142	59 / 150	63 / 160	66 / 167.6	70 / 177.8	74 / 188
B	30.5 / 77.5	31 / 78.7	31.5 / 80	31.5 / 80	32 / 81.3	32.5 / 82.6	33 / 83.8	33.5 / 85.1
C	12.5 / 31.8	12.5 / 31.8	13 / 33	13.3 / 33.8	13.7 / 34.8	14 / 35.6	14.5 / 36.8	15 / 38
D	25.5 / 64.8	26 / 66	26.5 / 67.3	27 / 68.6	27.5 / 69.9	28 / 71	28.5 / 72.4	29 / 73.7

BARCODES

ITEM	BAG	DOZEN	CASE
■ 333-1770-LY/S	616314159695	---	02616314159693
■ 333-1770-LY/M	616314118586	---	02616314118584
■ 333-1770-LY/L	616314118579	---	02616314118577
■ 333-1770-LY/XL	616314118593	---	02616314118591
■ 333-1770-LY/2XL	616314118609	---	02616314118607
■ 333-1770-LY/3XL	616314118616	---	02616314118614
■ 333-1770-LY/4XL	616314118623	---	02616314118621
■ 333-1770-LY/5XL	616314118630	---	02616314118638
■ 333-1770-OR/S	616314172052	---	02616314172050
■ 333-1770-OR/M	616314146923	---	02616314146921
■ 333-1770-OR/L	616314146930	---	02616314146938
■ 333-1770-OR/XL	616314146916	---	02616314146914
■ 333-1770-OR/2XL	616314146947	---	02616314146945
■ 333-1770-OR/3XL	616314146954	---	02616314146952
■ 333-1770-OR/4XL	616314146961	---	02616314146969
■ 333-1770-OR/5XL	616314146978	---	02616314146976

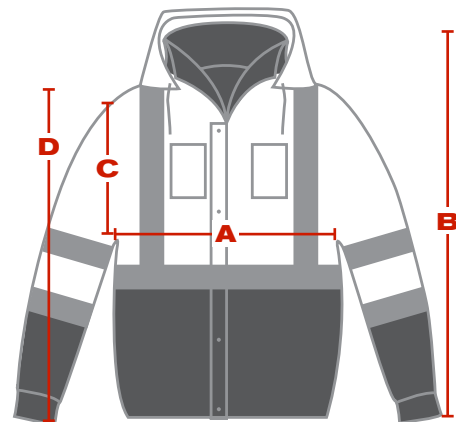

PROTECTIVE INDUSTRIAL PRODUCTS, INC. | BRINGING THE BEST OF THE WORLD TO YOU®

AMERICAS: (800) 262-5755 • (518) 861-0133 | EUROPE: +34-96182-41-48 | AMEA: (ASIA, MIDDLE EAST, AFRICA) 852-2475-9228 | www.pipglobal.com

This document and the information contained herein is the property of Protective Industrial Products, Inc. (PIP) and may not be used or reproduced without permission. Product users should conduct all appropriate testing or other evaluations to determine the suitability of PIP products for a particular purpose or use within a particular environment. PIP DISCLAIMS ALL WARRANTIES OTHER THAN AS EXPRESSLY PROVIDED.