



SPECIFICATION SHEET

33-4250R



G-TEK® HV HI-VIS SEAMLESS KNIT POLYESTER GLOVE WITH POLYURETHANE COATED SMOOTH GRIP

- 13 gauge, seamless knit polyester shell offers increased comfort, finger dexterity and breathability
- Polyurethane (PU) coatings offer great puncture and abrasion resistance while offering excellent tactile sensitivity
- Knit Wrist helps prevent dirt and debris from entering the glove
- Breathable back for comfort
- Hi-Vis coloring makes this product very easy to see
- CFIA Approved

APPLICATIONS

- Electronic and computer assembly
- Quality control
- Inspection
- General assembly

CARE INSTRUCTIONS

Recommend washing gloves in tempered water not exceeding 104° F or 40°C. A mild non-ionic laundry soap or detergent should be used. Wash in a 5-10 minute cycle time. Rinse in cold water. Tumble dry at temperature not exceeding 140° F or 60° C.

TECHNICAL DATA

MATERIAL	Polyester with urethane coating on palm and fingers					
COLOR	Hi Vis Orange					
CUFF STYLE	Continuous Knit					
SIZES	XS - XXL					
PACKAGING	1 pair per bag, 12 pairs per dozen, 25 dozen per case					
CASE	24.4" x 11.1" x 18.1" / 62cm x 28cm x 46cm					
CASE WEIGHT	XS	S	M	L	XL	XXL
	17.6 lbs 8.0 kg	18.7 lbs 8.5 kg	19.8 lbs 9.0 kg	20.9 lbs 9.5 kg	22.0 lbs 10.0 kg	23.1 lbs 10.5 kg
COO	China					



DIMENSIONS (in/cm)


	XS	S	M	L	XL	XXL
A	7.5 / 19.0	8.5 / 21.5	8.9 / 22.5	9.3 / 23.5	9.6 / 24.5	10.0 / 25.5
B	3.2 / 8.2	3.3 / 8.4	3.4 / 8.7	3.7 / 9.5	3.9 / 9.9	4.1 / 10.3
H	■ Purple	■ Red	■ Yellow	■ Brown	■ Black	■ Blue

PERFORMANCE PROPERTIES

EN388: 3131						
ABRASION	0	1	2	3	4	5
CUT	0	1	2	3	4	5
TEAR	0	1	2	3	4	5
PUNCTURE	0	1	2	3	4	5

BARCODES

ITEM	BAG	DOZEN	CASE
■ 33-4250R/XS	---	01616314092113	02616314092112
■ 33-4250R/S	---	01616314092120	02616314092129
■ 33-4250R/M	---	01616314092137	02616314092136
■ 33-4250R/L	---	01616314092144	02616314092143
■ 33-4250R/XL	---	01616314092151	02616314092150
■ 33-4250R/XXL	---	01616314092168	02616314092167

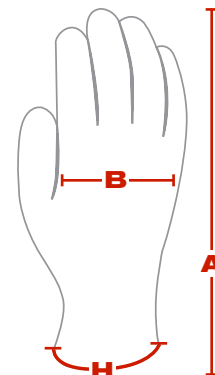

PROTECTIVE INDUSTRIAL PRODUCTS, INC. | BRINGING THE BEST OF THE WORLD TO YOU®

AMERICAS: (800) 262-5755 • (518) 861-0133 | EUROPE: +34-96182-41-48 | AMEA: (ASIA, MIDDLE EAST, AFRICA) 852-2475-9228 | www.pipglobal.com

This document and the information contained herein is the property of Protective Industrial Products, Inc. (PIP) and may not be used or reproduced without permission. Product users should conduct all appropriate testing or other evaluations to determine the suitability of PIP products for a particular purpose or use within a particular environment. PIP DISCLAIMS ALL WARRANTIES OTHER THAN AS EXPRESSLY PROVIDED.