



SPECIFICATION SHEET

33-825



G-TEK® MEDIUM WEIGHT SEAMLESS KNIT NYLON GLOVE WITH POLYURETHANE COATED SMOOTH GRIP

- 13 gauge, medium weight seamless knit nylon shell offers increased comfort, finger dexterity and breathability
- Polyurethane (PU) coatings offer great puncture and abrasion resistance while offering excellent tactile sensitivity
- Knit Wrist helps prevent dirt and debris from entering the glove
- Breathable back for comfort
- CFIA Approved

APPLICATIONS

- Electronic and computer assembly
- Quality control
- Inspection
- General assembly

CARE INSTRUCTIONS

Recommend washing gloves in tempered water not exceeding 104° F or 40°C. A mild non-ionic laundry soap or detergent should be used. Wash in a 5-10 minute cycle time. Rinse in cold water. Tumble dry at temperature not exceeding 140° F or 60° C.

TECHNICAL DATA

MATERIAL	Polyester with polyurethane coating on palm and fingers					
COLOR	Shell: ■ Green, Coating: ■ Black					
CUFF STYLE	Continuous Knit					
SIZES	XS - XXL					
PACKAGING	1 pair per bag, 12 pairs per dozen, 25 dozen per case					
CASE	24.8" x 11.0" x 18.1" / 63cm x 28cm x 46cm					
CASE WEIGHT	XS	S	M	L	XL	XXL
	17.6 lbs 8.0 kg	18.7 lbs 8.5 kg	19.8 lbs 9.0 kg	20.9 lbs 9.5 kg	22.0 lbs 10.0 kg	23.1 lbs 10.5 kg
COO	China					

PERFORMANCE PROPERTIES

EN388: 3121 ASTM F2992-15 ANSI Cut Level A1 (Adopted by ANSI/ISEA 02/16)
ASTM F1790-05 ANSI Cut Level 1

ABRASION	0	1	2	3	4	5
CUT	0	1	2	3	4	5
TEAR	0	1	2	3	4	5
PUNCTURE	0	1	2	3	4	5


BARCODES

ITEM	BAG	DOZEN	CASE
■ 33-825/XS	----	01616314092052	02616314092051
■ 33-825/S	----	01616314092069	02616314092068
■ 33-825/M	----	01616314092076	02616314092075
■ 33-825/L	----	01616314092083	02616314092082
■ 33-825/XL	----	01616314092090	02616314092099
■ 33-825/XXL	----	01616314092106	02616314092105



DIMENSIONS (in/cm)

	XS	S	M	L	XL	XXL
A	7.5 / 19.0	8.5 / 21.5	8.9 / 22.5	9.3 / 23.5	9.6 / 24.5	10.0 / 25.5
B	3.2 / 8.2	3.3 / 8.4	3.4 / 8.7	3.7 / 9.5	3.9 / 9.9	4.1 / 10.3
H	■ Purple	■ Red	■ Yellow	■ Brown	■ Black	■ Blue

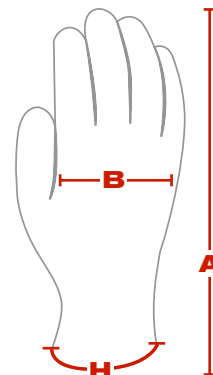

PROTECTIVE INDUSTRIAL PRODUCTS, INC. | BRINGING THE BEST OF THE WORLD TO YOU®

AMERICAS: (800) 262-5755 • (518) 861-0133 | EUROPE: +34-96182-41-48 | AMEA: (ASIA, MIDDLE EAST, AFRICA) 852-2475-9228 | www.pipglobal.com

This document and the information contained herein is the property of Protective Industrial Products, Inc. (PIP) and may not be used or reproduced without permission. Product users should conduct all appropriate testing or other evaluations to determine the suitability of PIP products for a particular purpose or use within a particular environment. PIP DISCLAIMS ALL WARRANTIES OTHER THAN AS EXPRESSLY PROVIDED.