



SPECIFICATION SHEET

34-225



G-TEK® NPG SEAMLESS KNIT NYLON GLOVE WITH NITRILE COATED SMOOTH GRIP ON PALM & FINGERS

- Seamless one-piece nylon shell offers increased comfort, finger dexterity and breathability
- Solid Dipped Nitrile coatings provide excellent dry grip and will not absorb liquids into the coating
- Knit Wrist helps prevent dirt and debris from entering the glove
- This style is also available tri-folded and shrink-wrapped for carefree dispensing through vending machines (34-225V)

APPLICATIONS

Ideal for manufacturing and assembly applications where abrasion, cut, and puncture resistance is required.

CARE INSTRUCTIONS

Recommend washing gloves in slightly warm water not exceeding 40°C. A mild non-ionic detergent should be used. A 5-10 minute cycle time should be employed. Tumble dry on low - maximum temperature 140°F (60°C)


TECHNICAL DATA

MATERIAL	Nylon with nitrile coating on palm and fingers				
COLOR	<input type="checkbox"/> White / <input checked="" type="checkbox"/> Gray				
CUFF STYLE	Continuous Knit				
SIZES	XS - XL				
PACKAGING	12 pairs per dozen, 25 dozen per case				
CASE	XS: 20.1" x 9.8" x 20.1" / 51cm x 25cm x 51cm S: 20.1" x 9.8" x 20.1" / 51cm x 25cm x 51cm M: 20.9" x 10.2" x 20.9" / 53cm x 26cm x 53cm L: 20.9" x 10.6" x 21.3" / 53cm x 27cm x 54cm XL: 20.9" x 10.6" x 21.3" / 53cm x 27cm x 54cm				
CASE WEIGHT	XS	S	M	L	XL
	27.5 lbs 12.5 kg	30 lbs 13.6 kg	33 lbs 15 kg	35 lbs 15.9 kg	35 lbs 15.9 kg
COO	China				



DIMENSIONS (in/cm)

	XS	S	M	L	XL
A	7.9 / 20	8.9 / 22.5	9.4 / 24	9.8 / 25	10.2 / 26
B	3.2 / 8.2	3.3 / 8.5	3.5 / 9	3.7 / 9.5	3.9 / 10
H	<input checked="" type="checkbox"/> Blue	<input type="checkbox"/> White	<input checked="" type="checkbox"/> Green	<input checked="" type="checkbox"/> Brown	<input checked="" type="checkbox"/> Yellow

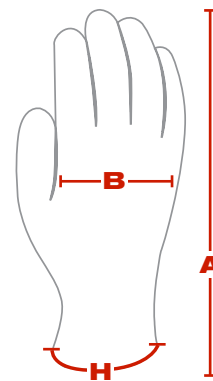

PERFORMANCE PROPERTIES

EN388: 4221						
ABRASION	0	1	2	3	4	5
CUT	0	1	2	3	4	5
TEAR	0	1	2	3	4	5
PUNCTURE	0	1	2	3	4	5

BARCODES

ITEM	BAG	DOZEN	CASE
<input type="checkbox"/> 34-225/XS	--	01616314021206	02616314021206
<input type="checkbox"/> 34-225/S	--	01616314011467	02616314011467
<input type="checkbox"/> 34-225/M	--	01616314011474	02616314011474
<input type="checkbox"/> 34-225/L	--	01616314011481	02616314011481
<input type="checkbox"/> 34-225/XL	--	01616314011498	02616314011498