



SPECIFICATION SHEET

343-1755



ANSI TYPE R CLASS 3 VALUE INSULATED WINTER COAT

- Durable waterproof polyester with taped seams
- Quilted poly-fil insulation on body and sleeves
- 2" silver reflective tape
- Hideaway hood
- Black bottom and trim
- Zipper closure with storm flap secured with snaps
- Adjustable cuffs
- 2 external pockets with storm flaps
- Upper radio pocket

APPLICATIONS

- Construction
- Municipal
- Shipyards
- Anywhere hi-visibility apparel is necessary

CARE INSTRUCTIONS

Recommend washing in tempered water not exceeding 104°F or 40°C. Wash in a 5-10 minute cycle time or hand wash. Rinse in cold water. Tumble dry at temperature not exceeding 104°F or 40°C, do not wring. Do not wash in biological powder, wash as synthetics. Maximum of 10 wash cycles

TECHNICAL DATA

MATERIAL	100% Polyester
CONSTRUCTION	Main: : 185g/m ² 100% polyester 300D Oxford with PU coating Lining: 190T Nylon, 190T Nylon PVC, black 190T, lime yellow/orange. Insulation: 40g/m ² 100% polyfil on bottom, 160g/m ² 100% polyfil on body Acc: : #8 Resin 2 way zipper, Left into Right snaps.
COLOR	■ Hi-Vis Lime Yellow or ■ Hi-Vis Orange
SIZES	S - 5X
PACKAGING	1 per polybag, 10 per case
CASE DIMENSIONS	26.4" x 16.1" x 16.9" / 67cm x 41cm x 43cm
CASE WEIGHT	29.7 lbs / 13.5 kg
COO	China


BARCODES

ITEM	BAG	DOZEN	CASE
■ 343-1755-YEL/S	616314061929	01616314061928	02616314061927
■ 343-1755-YEL/M	616314061660	01616314061669	02616314061668
■ 343-1755-YEL/L	616314061110	01616314061119	02616314061118
■ 343-1755-YEL/XL	616314066382	01616314066381	02616314066380
■ 343-1755-YEL/2X	616314061066	01616314061065	02616314061064
■ 343-1755-YEL/3X	616314061073	01616314061072	02616314061071
■ 343-1755-YEL/4X	616314061080	01616314061089	02616314061088
■ 343-1755-YEL/5X	616314061097	01616314061096	02616314061095
■ 343-1755-OR/M	616314118975	---	02616314118973
■ 343-1755-OR/L	616314118968	---	02616314118966
■ 343-1755-OR/XL	616314118982	---	02616314118980
■ 343-1755-OR/2X	616314118999	---	02616314118997
■ 343-1755-OR/3X	616314119002	---	02616314119000
■ 343-1755-OR/4X	616314119019	---	02616314119017
■ 343-1755-OR/5X	616314119026	---	02616314119024



DIMENSIONS (in)

	S	M	L	XL	2X	3X	4X	5X
A	46 / 116.8	50 / 127	54 / 137	58 / 147.3	62 / 157.5	66 / 167.6	70 / 177.8	74 / 188
B	34.5 / 87.6	34.5 / 87.6	35.5 / 90	35.5 / 90	36.5 / 92.7	36.5 / 92.7	37.5 / 95.3	37.5 / 95.3
C	31.5 / 80	32 / 81.3	33 / 83.8	33.5 / 85.1	34 / 86.4	34.5 / 87.6	35 / 88.9	35.5 / 90.2

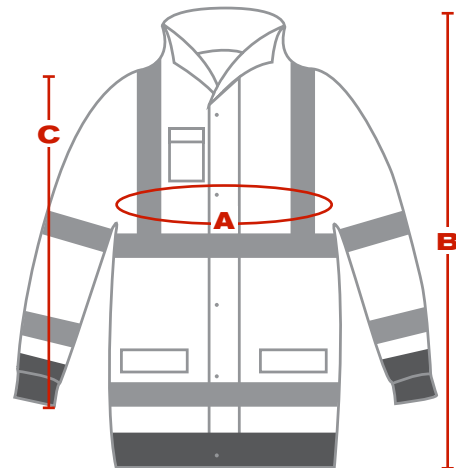

PROTECTIVE INDUSTRIAL PRODUCTS, INC. | BRINGING THE BEST OF THE WORLD TO YOU®

AMERICAS: (800) 262-5755 • (518) 861-0133 | EUROPE: +34-96182-41-48 | AMEA: (ASIA, MIDDLE EAST, AFRICA) 852-2475-9228 | www.pipglobal.com

This document and the information contained herein is the property of Protective Industrial Products, Inc. (PIP) and may not be used or reproduced without permission. Product users should conduct all appropriate testing or other evaluations to determine the suitability of PIP products for a particular purpose or use within a particular environment. PIP DISCLAIMS ALL WARRANTIES OTHER THAN AS EXPRESSLY PROVIDED.