

SPECIFICATION SHEET

343-1756



ANSI TYPE R CLASS 3 7-IN-1 ALL CONDITIONS COAT WITH INNER JACKET & VEST COMBINATION

- Durable waterproof polyester with taped seams
- Lined with polyester mesh and smooth taffeta nylon
- High fleece lined collar with rollaway hood
- Heavy duty zipper closure with storm flap secured with snaps
- 2" 3M Scotchlite silver reflective material
- Fully reversible to black with zip-off sleeves
- 2 lower flap pockets, 1 ID pocket, 1 radio pocket
- Internal upper pen pockets and zippered hideaway pocket,
1 internal lower pocket with tab closure

APPLICATIONS

- Construction
- Municipal
- Shipyards
- Anywhere hi-visibility apparel is necessary

CARE INSTRUCTIONS

Recommend washing in tempered water not exceeding 104°F or 40°C. Wash in a 5-10 minute cycle time or hand wash. Rinse in cold water. Tumble dry at temperature not exceeding 104°F or 40°C, do not wring. Do not wash in biological powder, wash as synthetics. Maximum of 25 wash cycles

TECHNICAL DATA

MATERIAL	100% Polyester
CONSTRUCTION	Main: 190g/m ² 100% polyester 300D Oxford with PU coating Insulated Lining: 40g neutral cotton, 160g/m ² 100% quilted padding Closure: #5 Resin 2 way zipper
COLOR	■ Hi-Vis Lime Yellow or ■ Hi-Vis Orange
SIZES	S - 5X
PACKAGING	1 per polybag, 10 per case
CASE DIMENSIONS	26.4" x 16.9" x 16.9" / 67cm x 43cm x 43cm
CASE WEIGHT	51 lb / 23.5 kg
COO	China


BARCODES

ITEM	BAG	DOZEN	CASE
343-1756-YEL/S	01616314066459	---	02616314066458
343-1756-YEL/ M	01616314066442	---	02616314066441
343-1756-LY/L	01616314066435	---	02616314066434
343-1756-LY/XL	01616314079381	---	02616314079380
343-1756-LY/2X	01616314066398	---	02616314066397
343-1756-LY/3X	01616314066404	---	02616314066403
343-1756-LY/4X	01616314066411	---	02616314066410
343-1756-LY/5X	01616314066428	---	02616314066427
343-1756-OR/S	01616314082121	---	02616314082120
343-1756-OR/ M	01616314082138	---	02616314082137
343-1756-OR/L	01616314082145	---	02616314082144
343-1756-OR/XL	01616314082152	---	02616314082151
343-1756-OR/2X	01616314082169	---	02616314082168
343-1756-OR/3X	01616314082176	---	02616314082175
343-1756-OR/4X	01616314082183	---	02616314082182
343-1756-OR/5X	01616314082190	---	02616314082189



DIMENSIONS (in/cm)

	S	M	L	XL	2X	3X	4X	5X
A	48 / 121.9	52.6 / 133.6	55.5 / 141	58.5 / 148.6	61.4 / 156	64.4 / 163.6	67.3 / 170.9	70.3 / 178.6
B	34.5 / 87.6	34.5 / 87.6	35 / 88.9	35 / 88.9	36.2 / 91.9	36.2 / 91.9	37 / 94	37 / 94
C	25 / 63.5	25 / 63.5	25.5 / 64.8	25.5 / 64.8	26 / 66	26 / 66	27 / 68.6	27 / 68.6

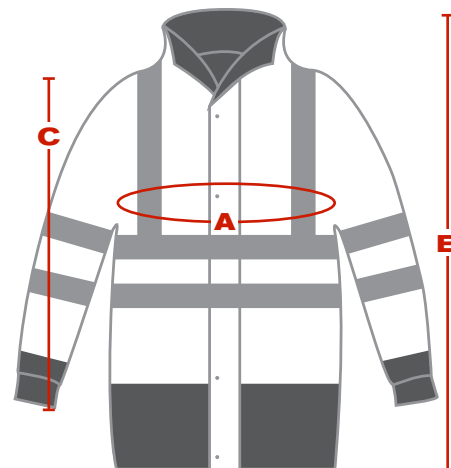

PROTECTIVE INDUSTRIAL PRODUCTS, INC. | BRINGING THE BEST OF THE WORLD TO YOU®

AMERICAS: (800) 262-5755 • (518) 861-0133 | EUROPE: +34-96182-41-48 | AMEA: (ASIA, MIDDLE EAST, AFRICA) 852-2475-9228 | www.pipglobal.com