



SPECIFICATION SHEET

34-8014



MAXIFLEX® ULTIMATE™ HI-VIS SEAMLESS KNIT NYLON GLOVE WITH NITRILE COATED MICRO-FOAM GRIP

- MaxiFlex® Ultimate by ATG®, hi-vis seamless knit nylon orange liner, black micro-foam nitrile coated palm and fingertips
- Minimal penetration (strike through) keeps the liner soft on the inside of the glove
- Excellent dexterity, sensitivity and tactility - breathable coating keeps hands cool and dry
- Non-marking to reduce product contamination
- Designed to produce minimal lint and dust
- Silicone-free
- CFIA Approved

APPLICATIONS

- General Assembly
- Micro-engineering
- Automotive components
- Painting
- Horticulture

CARE INSTRUCTIONS

Recommend washing gloves in tempered water not exceeding 104° F or 40°C. A mild commercial laundry soap or detergent should be used. Wash in a 5-10 minute cycle time. Rinse in cold water. Tumble dry at temperature not exceeding 104° F or 40° C.

TECHNICAL DATA

MATERIAL	Nitrile, nylon, Lycra®				
COLOR	Shell: ■ Orange / Grip: ■ Black				
CUFF STYLE	Knitwrist				
SIZES	S - XXL				
PACKAGING	12 per dozen, 12 dozen per case				
CASE	22.0" x 14.2" x 7.9" / 56.0cm x 36.0cm x 20.0cm				
CASE WEIGHT	S	M	L	XL	XXL
	13.2 lbs 6.0 kg	15.0 lbs 6.8 kg	15.7 lbs 7.1 kg	16.3 lbs 7.4 kg	17.0 lbs 7.7 kg
COO	Sri Lanka				

PERFORMANCE PROPERTIES

EN388: 4131						
ABRASION	0	1	2	3	4	5
CUT	0	1	2	3	4	5
TEAR	0	1	2	3	4	5
PUNCTURE	0	1	2	3	4	5


BARCODES

ITEM	BAG	DOZEN	CASE
■ 34-8014/S	----	01616314079091	02616314079090
■ 34-8014/M	----	01616314079107	02616314079106
■ 34-8014/L	----	01616314057723	02616314057722
■ 34-8014/XL	----	01616314079114	02616314079113
■ 34-8014/XXL	----	01616314079121	02616314079120



DIMENSIONS (in/cm)

	S	M	L	XL	XXL
A	8.1 / 20.5	8.5 / 21.5	8.7 / 22.0	8.9 / 22.5	9.1 / 23.0
B	3.2 / 8.2	3.3 / 8.4	3.7 / 9.4	3.8 / 9.7	3.9 / 10.0
H	□ White	■ Green	■ Brown	■ Yellow	■ Grey

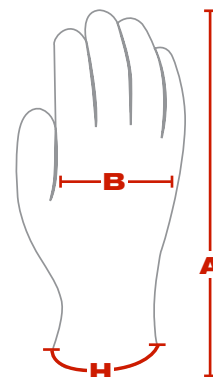

PROTECTIVE INDUSTRIAL PRODUCTS, INC. | BRINGING THE BEST OF THE WORLD TO YOU®

968 Albany Shaker Road | Latham, NY 12110 | 800-262-5755 | 518-861-0133 | Fax: 518-861-0144 | sales@pipusa.com | www.pipusa.com

This document and the information contained herein is the property of Protective Industrial Products, Inc. (PIP) and may not be used or reproduced without permission. Product users should conduct all appropriate testing or other evaluations to determine the suitability of PIP products for a particular purpose or use within a particular environment. PIP DISCLAIMS ALL WARRANTIES OTHER THAN AS EXPRESSLY PROVIDED.