



SPECIFICATION SHEET

34-8443



MAXIFLEX® CUT™ BY ATG®, BLACK MICRO-FOAM NITRILE COATED

- The world standard for precision handling in dry environments
- CutTech technology to develop our own unique high performance yarns and fibers that offer cut protection
- Patented micro-foam nitrile coating offers 360° breathability
- Reinforcement between the thumb and forefinger, improves cut resistance and extends glove life
- Optimized grip delivered through our micro-cup finish
- Minimal penetration (strike through) leaving only the soft liner resting against the skin
- This style is also available tri-folded and shrink-wrapped for carefree dispensing through vending machines (34-8443V)

APPLICATIONS

- Gardening and DIY
- Finishing and inspection
- Handling of small oily parts and components
- Assembly and Maintenance
- Logistics and warehousing
- Wiring operations

CARE INSTRUCTIONS

Recommend washing gloves in slightly warm water not exceeding 40°C. A mild non-ionic detergent should be used. A 5-10 minute cycle time should be employed. Tumble dry on low - maximum temperature 140°F (60°C)

TECHNICAL DATA

MATERIAL	Seamless knit engineered yarn, micro-foam nitrile dot nitrile coating					
COLOR	Shell: ■ Green / Coating: ■ Black					
CUFF STYLE	Continuous Knit					
SIZES	XS - XXL					
PACKAGING	12 per dozen, 6 dozen per case					
CASE	19.7" x 11.6" x 7.9" / 50cm x 29.5cm x 20cm					
CASE WEIGHT	XS	S	M	L	XL	XXL
	8.3 lbs 3.75 kg	8.8 lbs 4 kg	9.5 lbs 4.3 kg	9.9 lbs 4.5 kg	10.25 lbs 4.65 kg	10.6 lbs 4.8 kg
COO	Sri Lanka					

PERFORMANCE PROPERTIES

EN388: 4331	ASTM F1790-05 ANSI Cut Level 2					
ABRASION	0	1	2	3	4	5
CUT	0	1	2	3	4	5
TEAR	0	1	2	3	4	5
PUNCTURE	0	1	2	3	4	5


BARCODES

ITEM	PAIR	DOZEN	CASE
■ 34-8443/XS	616314156274	01616314156273	02616314156272
■ 34-8443/S	616314156250	01616314156259	02616314156258
■ 34-8443/M	616314156243	01616314156242	02616314156241
■ 34-8443/L	616314156236	01616314156235	02616314156234
■ 34-8443/XL	616314156267	01616314156266	02616314156265
■ 34-8443/XXL	616314156281	01616314156280	02616314156289



DIMENSIONS (in/cm)

	XS	S	M	L	XL	XXL
A	8 / 20.5	8.5 / 21.5	8.9 / 22.5	9.3 / 23.5	9.6 / 24.5	9.8 / 25.0
B	3.5 / 8.4	3.5 / 8.9	3.7 / 9.6	3.8 / 9.8	3.9 / 10	4 / 10.2
H	■ Blue	□ White	■ Green	■ Brown	■ Yellow	■ Grey

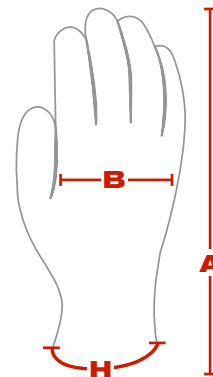

PROTECTIVE INDUSTRIAL PRODUCTS, INC. | BRINGING THE BEST OF THE WORLD TO YOU®

AMERICAS: (800) 262-5755 • (518) 861-0133 | EUROPE: +34-96182-41-48 | AMEA: (ASIA, MIDDLE EAST, AFRICA) 852-2475-9228 | www.pipglobal.com

This document and the information contained herein is the property of Protective Industrial Products, Inc. (PIP) and may not be used or reproduced without permission. Product users should conduct all appropriate testing or other evaluations to determine the suitability of PIP products for a particular purpose or use within a particular environment. PIP DISCLAIMS ALL WARRANTIES OTHER THAN AS EXPRESSLY PROVIDED.