



SPECIFICATION SHEET

34-8743FY



4331

MAXIFLEX® CUT™ HI-VIS SEAMLESS KNIT GLOVE WITH HI-VIS NITRILE MICRO-FOAM COATED

- The world standard for precision handling in dry environments
- CutTech technology to develop our own unique high performance yarns and fibers that offer cut protection
- Patented micro-foam nitrile coating offers 360° breathability
- Reinforcement between the thumb and forefinger, improves cut resistance and extends glove life
- Optimized grip delivered through our micro-cup finish
- Minimal penetration (strike through) leaving only the soft liner resting against the skin
- Made from component material which comply with Federal regulations for food contact, 21 CFR, 170-199

APPLICATIONS

- DIY
- Finishing and inspection
- Gardening
- Handling of small oily parts and components
- Assembly
- Maintenance
- Logistics and warehousing
- Wiring operations

CARE INSTRUCTIONS

Recommend washing gloves in slightly warm water not exceeding 40°C. A mild non-ionic detergent should be used. A 5-10 minute cycle time should be employed. Tumble dry on low - maximum temperature 140°F (60°C)

TECHNICAL DATA

MATERIAL	Seamless knit engineered yarn, micro-foam nitrile coating					
COLOR	Hi-Vis Yellow					
CUFF STYLE	Continuous Knit					
SIZES	XS - XXL					
PACKAGING	12 pair per dozen, 6 dozen per case					
CASE	19.7" x 11.6" x 7.9" / 50cm x 29.5cm x 20cm					
CASE WEIGHT	XS	S	M	L	XL	XXL
	13.2 lbs 6 kg	13.8 lbs 6.25 kg	15 lbs 6.8 kg	15.7 lbs 7.1 kg	16.3 lbs 7.4 kg	16.8 lbs 7.6 kg
COO	Sri Lanka					

PERFORMANCE PROPERTIES

EN388: 4331 ASTM F2992-15 ANSI Cut Level A2 (Adopted by ANSI/ISEA 02/16)
ASTM F1790-05 ANSI Cut Level 2

ABRASION	0	1	2	3	4	5
CUT	0	1	2	3	4	5
TEAR	0	1	2	3	4	5
PUNCTURE	0	1	2	3	4	5




BARCODES

ITEM	PAIR	DOZEN	CASE
34-8743FY/XS	616314206597	01616314206596	02616314206595
34-8743FY/S	616314184406	01616314184405	02616314184404
34-8743FY/M	616314184390	01616314184399	02616314184398
34-8743FY/L	616314184383	01616314184382	02616314184381
34-8743FY/XL	616314184413	01616314184412	02616314184411
34-8743FY/XXL	616314184420	01616314184429	02616314184428

DIMENSIONS (in/cm)

	XS	S	M	L	XL	XXL
A	8.07 / 20.5	8.46 / 21.5	8.86 / 22.5	9.06 / 23	9.45 / 24	9.65 / 24.5
B	3.4 / 8.6	3.5 / 8.8	3.7 / 9.4	3.8 / 9.6	3.9 / 9.8	3.9 / 10
H	Blue	White	Green	Brown	Yellow	Gray

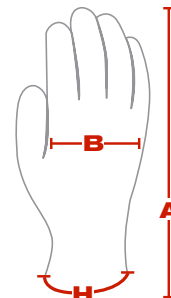

PROTECTIVE INDUSTRIAL PRODUCTS, INC. | BRINGING THE BEST OF THE WORLD TO YOU®

AMERICAS: (800) 262-5755 • (518) 861-0133 | EUROPE: +34-96182-41-48 | AMEA: (ASIA, MIDDLE EAST, AFRICA) 852-2475-9228 | www.pipglobal.com

This document and the information contained herein is the property of Protective Industrial Products, Inc. (PIP) and may not be used or reproduced without permission. Product users should conduct all appropriate testing or other evaluations to determine the suitability of PIP products for a particular purpose or use within a particular environment. PIP DISCLAIMS ALL WARRANTIES OTHER THAN AS EXPRESSLY PROVIDED.