



SPECIFICATION SHEET

34-874FY



MAXIFLEX® ULTIMATE™ HI-VIS SEAMLESS KNIT NYLON / LYCRA® GLOVE WITH HI-VIS NITRILE COATED MICRO-FOAM GRIP

- Micro-Foam Nitrile coatings are compatible with light oils and will provide a good grip and excellent abrasion resistance
- Hi-Vis coloring makes this product very easy to see
- Knit Wrist helps prevent dirt and debris from entering the glove
- 100% Silicone-free
- Patented micro-foam nitrile coating offers 360° breathability,
- 25% thinner than most foam nitrile gloves on the market
- Mimics the “hand at rest”, reducing hand fatigue & increasing comfort
- The micro-cup finish allows for a controlled and optimized grip
- CFIA Approved
- Made from component material which comply with Federal regulations for food contact, 21CFR, 170-199

APPLICATIONS

- General assembly
- Micro-engineering
- Automotive components
- Painting
- Horticulture

CARE INSTRUCTIONS

Recommend washing gloves in slightly warm water not exceeding 40°C. A mild non-ionic detergent should be used. A 5-10 minute cycle time should be employed. Tumble dry on low - maximum temperature 140°F (60°C).



TECHNICAL DATA

MATERIAL	Seamless nylon with Lycra® liner; micro-foam nitrile coating				
COLOR	Hi-Vis Yellow				
CUFF STYLE	Continuous Knit				
SIZES	S - XXL				
PACKAGING	12 pair per dozen, 6 dozen per case				
CASE	19.7" x 11.6" x 10.6" / 50cm x 29.5cm x 27cm				
CASE WEIGHT	S	M	L	XL	XXL
	13.2 lbs 6.0 kg	15.0 lbs 6.8 kg	15.7 lbs 7.1 kg	16.3 lbs 7.4 kg	17.0 lbs 7.7 kg
COO	Sri Lanka				

PERFORMANCE PROPERTIES

EN388: 4131 ASTM F2992-15 ANSI Cut Level A1 (Adopted by ANSI/ISEA 02/16)
ASTM F1790-05 ANSI Cut Level 1


ABRASION	0	1	2	3	4	-
CUT	0	1	2	3	4	5
TEAR	0	1	2	3	4	-
PUNCTURE	0	1	2	3	4	-

BARCODES

ITEM	PAIR	DOZEN	CASE
34-874FY/XXL	---	01616314128249	02616314128248
34-874FY/XL	---	01616314128232	02616314128231
34-874FY/L	---	01616314128201	02616314128200
34-874FY/M	---	01616314128218	02616314128217
34-874FY/S	---	01616314128225	02616314128224

DIMENSIONS (in/cm)

	S	M	L	XL	XXL
A	8.1 / 20.5	8.5 / 21.5	8.7 / 22.0	8.9 / 22.5	9.1 / 23.0
B	3.2 / 8.2	3.3 / 8.4	3.7 / 9.4	3.8 / 9.7	3.9 / 10.0
H	Red	Orange	White	Yellow	Black

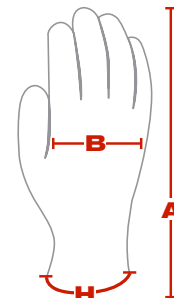

PROTECTIVE INDUSTRIAL PRODUCTS, INC. | BRINGING THE BEST OF THE WORLD TO YOU®

AMERICAS: (800) 262-5755 • (518) 861-0133 | EUROPE: +34-96182-41-48 | AMEA: (ASIA, MIDDLE EAST, AFRICA) 852-2475-9228 | www.pipglobal.com

This document and the information contained herein is the property of Protective Industrial Products, Inc. (PIP) and may not be used or reproduced without permission. Product users should conduct all appropriate testing or other evaluations to determine the suitability of PIP products for a particular purpose or use within a particular environment. PIP DISCLAIMS ALL WARRANTIES OTHER THAN AS EXPRESSLY PROVIDED.