



SPECIFICATION SHEET

34-874



4131

MAXIFLEX® ULTIMATE™ SEAMLESS KNIT NYLON / LYCRA® GLOVE WITH NITRILE COATED MICRO-FOAM GRIP

- Micro-Foam Nitrile coatings are compatible with light oils and will provide a good grip and excellent abrasion resistance
- Knit Wrist helps prevent dirt and debris from entering the glove
- 100% Silicone-free
- Patented micro-foam nitrile coating offers 360° breathability,
- 25% thinner than most foam nitrile gloves on the market
- Mimics the "hand at rest", reducing hand fatigue & increasing comfort
- The micro-cup finish allows for a controlled and optimized grip
- CFIA Approved
- Made from component material which comply with Federal regulations for food contact, 21CFR, 170-199

APPLICATIONS

- General assembly
- Micro-engineering
- Automotive components
- Painting
- Horticulture

CARE INSTRUCTIONS

Recommend washing gloves in slightly warm water not exceeding 40°C. A mild non-ionic detergent should be used. A 5-10 minute cycle time should be employed. Tumble dry on low - maximum temperature 140°F (60°C).

TECHNICAL DATA

MATERIAL	Seamless nylon with Lycra® liner; micro-foam nitrile coating						
COLOR	■ Black / Gray						
CUFF STYLE	Continuous Knit						
SIZES	XXS-XXXL						
PACKAGING	12 pair per dozen, 12 dozen per case						
CASE	19.7" x 11.6" x 10.6" / 50cm x 29.5cm x 27cm						
CASE WEIGHT	XXS	XS	S	M	L	XL	XXL
	11.2 lbs 5.1 kg	11.9 lbs 5.4 kg	13.2 lbs 6.0 kg	15.0 lbs 6.8 kg	15.7 lbs 7.1 kg	16.3 lbs 7.4 kg	17.0 lbs 7.7 kg
COO	Sri Lanka						

PERFORMANCE PROPERTIES

EN388: 4131 ASTM F2992-15 ANSI Cut Level A1 (Adopted by ANSI/ISEA 02/16)
ASTM F1790-05 ANSI Cut Level 1

ABRASION	0	1	2	3	4	-
CUT	0	1	2	3	4	5
TEAR	0	1	2	3	4	-
PUNCTURE	0	1	2	3	4	-




BARCODES

ITEM	PAIR	DOZEN	CASE
■ 34-874/XXS	---	01616314020346	02616314020346
■ 34-874/XS	---	01616314017940	02616314017940
■ 34-874/S	---	01616314017957	02616314017957
■ 34-874/M	---	01616314017964	02616314017964
■ 34-874/L	---	01616314017971	02616314017971
■ 34-874/XL	---	01616314017988	02616314017988
■ 34-874/XXL	---	01616314066060	02616314066069
■ 34-874/XXXL	---	01616314125767	02616314125766

DIMENSIONS (in/cm)

	XXS	XS	S	M	L	XL	XXL	XXXL
A	7.3 / 18.5	7.7 / 19.5	8.1 / 20.5	8.5 / 21.5	8.7 / 22.0	8.9 / 22.5	9.1 / 23.0	9.4 / 24
B	3.0 / 7.5	3.1 / 8.0	3.2 / 8.2	3.3 / 8.4	3.7 / 9.4	3.8 / 9.7	3.9 / 10.0	4.1 / 10.5
H	■ Purple	■ Blue	■ White	■ Green	■ Brown	■ Yellow	■ Grey	■ Magenta

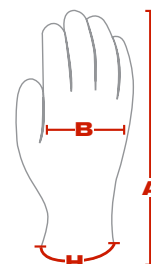

PROTECTIVE INDUSTRIAL PRODUCTS, INC. | BRINGING THE BEST OF THE WORLD TO YOU®

AMERICAS: (800) 262-5755 • (518) 861-0133 | EUROPE: +34-96182-41-48 | AMEA: (ASIA, MIDDLE EAST, AFRICA) 852-2475-9228 | www.pipglobal.com

This document and the information contained herein is the property of Protective Industrial Products, Inc. (PIP) and may not be used or reproduced without permission. Product users should conduct all appropriate testing or other evaluations to determine the suitability of PIP products for a particular purpose or use within a particular environment. PIP DISCLAIMS ALL WARRANTIES OTHER THAN AS EXPRESSLY PROVIDED.