



SPECIFICATION SHEET

353-2000

3M Scotchlite®
Reflective Material



FALCON™ VIZ PLUS ANSI TYPE R CLASS 3 HEAVY DUTY WATERPROOF BREATHABLE JACKET

- Waterproof breathable heavy duty 300 D 100% polyester outer shell
- Water-tight "D" ring harness access
- 3M Scotchlite reflective material
- Fully adjustable hood accommodates hard hat
- 4 pockets including clear ID holder
- 2 mic tabs
- Adjustable cuffs

APPLICATIONS

- Rainy work conditions
- Construction/Survey Crews
- Shipyards/Railyards
- Utilities

CARE INSTRUCTIONS

Recommend washing in tempered water not exceeding 104°F or 40°C. Wash in a 5-10 minute cycle time or hand wash. Rinse in cold water. Hang dry. Do not wash in biological powder, wash as synthetics. Maximum of 25 wash cycles.

TECHNICAL DATA

MATERIAL	100% Polyester
CONSTRUCTION	Outer: 300 Denier, 100% Polyester woven with waterproof breathable PU coating Lining: 115gsm mesh and polyester lining, gray, 115 gsm 100% Polyester brushed Tricot pocket lining, navy Accessories: 3M # 8906 reflective tape, resin zip for front fly, nylon zip for pockets, black plastic button, two tabs on chest
COLOR	■ Hi-Vis Yellow or, ■ Hi-Vis Orange
SIZES	S - 5X
PACKAGING	1 per polybag; 10 per case
CASE DIMENSIONS	22.8" x 17.7" x 11.78" / 58cm x 45cm x 30cm
CASE WEIGHT	19.8 lbs / 9 kg
COO	China


BARCODES

ITEM	BAG	BOX	CASE
■ 353-2000-LY/S	616314213014	01616314213013	02616314213012
■ 353-2000-LY/M	616314100154	01616314100153	02616314100152
■ 353-2000-LY/L	616314100147	01616314100146	02616314100145
■ 353-2000-LY/XL	616314100161	01616314100160	02616314100169
■ 353-2000-LY/2X	616314100178	01616314100177	02616314100176
■ 353-2000-LY/3X	616314100185	01616314100184	02616314100183
■ 353-2000-LY/4X	616314100192	01616314100191	02616314100190
■ 353-2000-LY/5X	616314100208	01616314100207	02616314100206
■ 353-2000-OR/S	616314213021	01616314213020	02616314213029
■ 353-2000-OR/M	616314199202	01616314199201	02616314199200
■ 353-2000-OR/L	616314199219	01616314199218	02616314199217
■ 353-2000-OR/XL	616314199226	01616314199225	02616314199224
■ 353-2000-OR/2X	616314199233	01616314199232	02616314199231
■ 353-2000-OR/3X	616314199240	01616314199249	02616314199248
■ 353-2000-OR/4X	616314199257	01616314199256	02616314199255
■ 353-2000-OR/5X	616314199264	01616314199263	02616314199262



DIMENSIONS (in/cm)

	S	M	L	XL	2X	3X	4X	5X
A	46/116.8	50/127	54/137.2	58/147.3	62/157.5	66/167.6	70/177.8	74/188
B	27/68.6	28/41.1	29/73.7	30/76.2	31/78.7	32/81.3	33/83.8	33/83.8

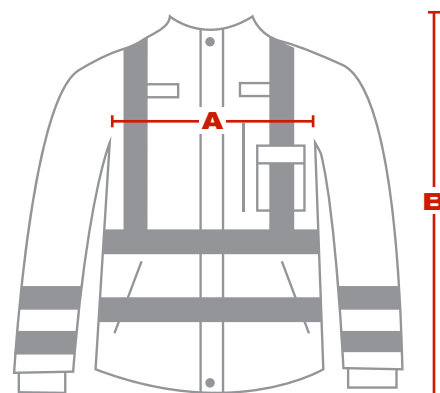

3M and Thinsulate are trademarks of 3M

PROTECTIVE INDUSTRIAL PRODUCTS, INC. | BRINGING THE BEST OF THE WORLD TO YOU®

AMERICAS: (800) 262-5755 • (518) 861-0133 | EUROPE: +34-96182-41-48 | AMEA: (ASIA, MIDDLE EAST, AFRICA) 852-2475-9228 | www.pipglobal.com

This document and the information contained herein is the property of Protective Industrial Products, Inc. (PIP) and may not be used or reproduced without permission. Product users should conduct all appropriate testing or other evaluations to determine the suitability of PIP products for a particular purpose or use within a particular environment. PIP DISCLAIMS ALL WARRANTIES OTHER THAN AS EXPRESSLY PROVIDED.