



SPECIFICATION SHEET

353-2001

3M Scotchlite®
Reflective Material



FALCON™ VIZ PLUS CLASS E HEAVY DUTY WATERPROOF BREATHABLE BIB

- Waterproof breathable heavy duty 300 D 100% polyester shell
- 3M Scotchlite reflective material
- High-backed design
- Front fly opening with snap
- Front chest security pocket
- Adjustable cuffs
- Sizes: M-5X

APPLICATIONS

- Rainy work conditions
- Construction/Survey Crews
- Shipyards/Railyards
- Utilities

CARE INSTRUCTIONS

Recommend washing in tempered water not exceeding 104°F or 40°C. Wash in a 5-10 minute cycle time or hand wash. Rinse in cold water. Hang dry. Do not wash in biological powder, wash as synthetics. Maximum of 25 wash cycles.

TECHNICAL DATA

MATERIAL	100% Polyester
CONSTRUCTION	300 Denier, 100% Polyester woven with waterproof breathable PU coating 3M # 8906 reflective tape
COLOR	■ Hi-Vis Yellow or, ■ Hi-Vis Orange
SIZES	S - 5X
PACKAGING	1 per polybag; 10 per case
CASE DIMENSIONS	18.9" x 10.2" x 7.9" / 48cm x 26cm x 20cm
CASE WEIGHT	10.5 lbs / 4.7 kg
COO	China


BARCODES

ITEM	BAG	BOX	CASE
■ 353-2001-LY/S	616314212994	01616314212993	02616314212992
■ 353-2001-LY/M	616314100222	01616314100221	02616314100220
■ 353-2001-LY/L	616314100215	01616314100214	02616314100213
■ 353-2001-LY/XL	616314100239	01616314100238	02616314100237
■ 353-2001-LY/2X	616314100246	01616314100245	02616314100244
■ 353-2001-LY/3X	616314100253	01616314100252	02616314100251
■ 353-2001-LY/4X	616314100260	01616314100269	02616314100268
■ 353-2001-LY/5X	616314100277	01616314100276	02616314100275
■ 353-2001-OR/S	616314213007	01616314213006	02616314213005
■ 353-2001-OR/M	616314199271	01616314199270	02616314199279
■ 353-2001-OR/L	616314199288	01616314199287	02616314199286
■ 353-2001-OR/XL	616314199295	01616314199294	02616314199293
■ 353-2001-OR/2X	616314199301	01616314199300	02616314199309
■ 353-2001-OR/3X	616314199318	01616314199317	02616314199316
■ 353-2001-OR/4X	616314199325	01616314199324	02616314199323
■ 353-2001-OR/5X	616314199332	01616314199331	02616314199330



DIMENSIONS (in/cm)

	S	M	L	XL	2X	3X	4X	5X
A	42/	46/116.8	50/127	54/137.2	58/147.3	62/157.5	66/167.6	70/177.8
B	27.5/69.8	29.5/75	31.5/80	31.5/80	31.5/80	31.5/80	31.5/80	31.5/80
C	7.7/19.5	8.2/20.75	8.7/22	9.2/23.3	9.6/24.5	10.1/25.8	10.6/27	11.1/28.3
D	9.75/23.5	9.75/23.5	9.75/23.5	10/25.4	10/25.4	10/25.4	10/25.4	10/25.4
E	24.3/61.7	25.3/ 64.1	26.3/66.7	27.3/69.2	28.3/71.8	29.3/74.3	30.3/76.8	31.3/79.3
F	25.3/ 64.1	26.3/66.7	27.2/69.2	28.3/71.8	29.3/74.3	30.3/76.8	31.3/79.3	32.3/82

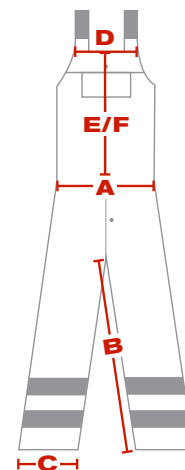

3M and Thinsulate are trademarks of 3M

PROTECTIVE INDUSTRIAL PRODUCTS, INC. | BRINGING THE BEST OF THE WORLD TO YOU®

AMERICAS: (800) 262-5755 • (518) 861-0133 | EUROPE: +34-96182-41-48 | AMEA: (ASIA, MIDDLE EAST, AFRICA) 852-2475-9228 | www.pipglobal.com

This document and the information contained herein is the property of Protective Industrial Products, Inc. (PIP) and may not be used or reproduced without permission. Product users should conduct all appropriate testing or other evaluations to determine the suitability of PIP products for a particular purpose or use within a particular environment. PIP DISCLAIMS ALL WARRANTIES OTHER THAN AS EXPRESSLY PROVIDED.