



SPECIFICATION SHEET

385-FRSC



8.5 CAL/CM² ARC/FR DUAL CERTIFIED COVERALL WITH ZIPPER CLOSURE

- ARC rating: ATPV 8.5 cal/cm², PPE 2 (HRC 2)
- Dual-certified to NFPA 70E and NFPA 2112-2012 standards
- 2 way front brass zipper on aramid tape
- Storm guard over front zipper
- 2 chest flap pockets, flap with snap closure
- Protective shirt collar; side elasticized waist
- 2 waist & 2 rear hip patch pockets
- Pen pocket on left sleeve, tool pocket on leg
- Arm cuffs with two position snap closure
- All metal thermally protected from the skin

STANDARDS MET

- NFPA2112-2012 UL certified
- NFPA 70E-2004, NFPA 1975-2009, ASTM F1506-2010a,
- CAN/CGSB 155.20-2000,CAN/CGSB 155.22-97,et OSHA 29 CFR1910.269
- EN ISO11611:2008, EN ISO11612:2008, EN ISO14116:2008

APPLICATIONS

- Oil and gas
- Petrochemical
- Electrical utilities
- Anywhere exposed to Flash Fire and/or Arc flash risk

CARE INSTRUCTIONS

Machine wash warm, tumble dry low with synthetic detergents. Wash separate from everyday clothing in small loads. FR clothing is dry cleanable. DO NOT use bleach, fabric softener or dryer sheets

TECHNICAL DATA

MATERIAL	90% Cotton / 10% Nylon
CONSTRUCTION	FR twill weave fabric with Aramid high tenacity FR thread
COLOR	■ Navy Blue, ■ Khaki
SIZES	S-6X
PACKAGING	1 per polybag; 18 per case
CASE	25" x 16.5" x 11.4" / 54cm x 41cm x 41cm
CASE WEIGHT	53lbs / 24kg
COO	China


BARCODES

ITEM	EACH	BOX	CASE
■ 385-FRSC-NV/S	616314164842	01616314163868	02616314163867
■ 385-FRSC-NV/M	616314164859	01616314163875	02616314163874
■ 385-FRSC-NV/L	616314164866	01616314163882	02616314163881
■ 385-FRSC-NV/XL	616314164873	01616314163899	02616314163898
■ 385-FRSC-NV/2X	616314164880	01616314163905	02616314163904
■ 385-FRSC-NV/3X	616314164897	01616314163905	02616314163904
■ 385-FRSC-NV/4X	616314164903	01616314163905	02616314163904
■ 385-FRSC-NV/5X	616314164910	01616314163905	02616314163904
■ 385-FRSC-KH/S	616314164767	01616314164766	02616314164765
■ 385-FRSC-KH/M	616314164774	01616314164773	02616314164772
■ 385-FRSC-KH/L	616314164781	01616314164780	02616314164789
■ 385-FRSC-KH/XL	616314164798	01616314164797	02616314164796
■ 385-FRSC-KH/2X	616314164804	01616314164803	02616314164802
■ 385-FRSC-KH/3X	616314164811	01616314164810	02616314164819
■ 385-FRSC-KH/4X	616314164828	01616314164827	02616314164826
■ 385-FRSC-KH/5X	616314164835	01616314164834	02616314164833



DIMENSIONS (in)

	S	M	L	XL	2X	3X	4X	5X	6X
A	36-38	40-42	44-46	48-50	52-54	56-58	60-62	64-66	68-70
B	32-34	36-38	40-42	44-46	48-50	52-54	56-58	60-62	64-66
C	34.5	35.5	36.5	38	39.5	41	42.5	44	45.5
D	32	32	32	32	32	32	32	32	32

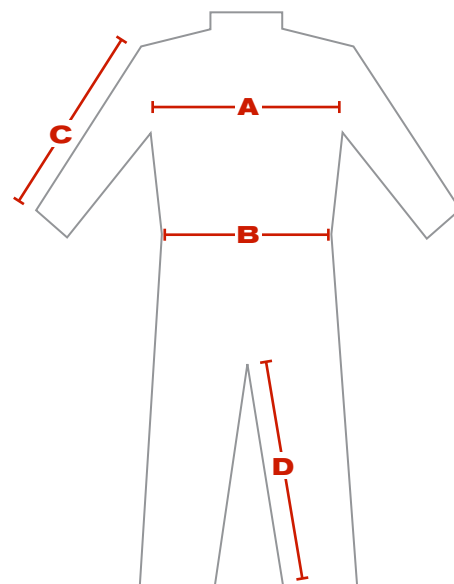

PROTECTIVE INDUSTRIAL PRODUCTS, INC. | BRINGING THE BEST OF THE WORLD TO YOU®

968 Albany Shaker Road | Latham, NY 12110 | 800-262-5755 | 518-861-0133 | Fax: 518-861-0144 | sales@pipusa.com | www.pipusa.com

This document and the information contained herein is the property of Protective Industrial Products, Inc. (PIP) and may not be used or reproduced without permission. Product users should conduct all appropriate testing or other evaluations to determine the suitability of PIP products for a particular purpose or use within a particular environment. PIP DISCLAIMS ALL WARRANTIES OTHER THAN AS EXPRESSLY PROVIDED.