



SPECIFICATION SHEET

44-3445



MAXICUT® ULTRA DT™ BY ATG®, PREMIUM BLUE ENGINEERED YARN SHELL, BLACK MICRO-FOAM NITRILE COATED W/NITRILE DOTS

- Micro-Foam nitrile coatings are compatible with light oils and will provide a good grip and excellent abrasion resistance
- Unique high performance yarns and fibers that offer cut protection while maintaining high levels of comfort
- Reinforcement between the thumb and forefinger
- Patented micro-foam nitrile coating offers 360° breathability making it the most breathable cut resistant glove on the market
- Optimized grip delivered through our micro-cup finish
- Minimal penetration (strike through) leaving only the soft liner resting against the skin
- The Skin Health Alliance has awarded professional dermatological accreditation following review of the scientific dossier behind this product

APPLICATIONS

- DIY
- Finishing and inspection
- Gardening
- Handling of small components
- Primary, secondary and final assembly
- Maintenance
- Logistics and warehousing
- Using tools and instruments

CARE INSTRUCTIONS

Recommend washing gloves in slightly warm water not exceeding 40°C. A mild non-ionic detergent should be used. A 5-10 minute cycle time should be employed. Tumble dry on low - maximum temperature 140°F (60°C)

TECHNICAL DATA

MATERIAL	Seamless knit engineered yarn, micro-foam nitrile coating					
COLOR	■ Blue/Black					
CUFF STYLE	Continuous Knit					
SIZES	XS - XXL					
PACKAGING	12 per dozen, 6 dozen per case					
CASE	19.7" x 11.6" x 7.9" / 50cm x 29.5cm x 20cm					
CASE WEIGHT	XS	S	M	L	XL	XXL
	9.3 lbs 4.2 kg	10.1 lbs 4.6 kg	10.8 lbs 4.9 kg	11.5 lbs 5.2 kg	12.1 lbs 5.5 kg	12.8 lbs 5.8 kg
COO	Sri Lanka					

PERFORMANCE PROPERTIES

EN388: 4542	ASTM F2992-15 ANSI Cut Level A3 (Adopted by ANSI/ISEA 02/16) ASTM F1790-05 ANSI Cut Level 3					
ABRASION	0	1	2	3	4	5
CUT	0	1	2	3	4	5
TEAR	0	1	2	3	4	5
PUNCTURE	0	1	2	3	4	5




BARCODES

ITEM	PAIR	DOZEN	CASE
■ 44-3445/XS	616314178337	01616314178336	02616314178335
■ 44-3445/S	616314178313	01616314178312	02616314178311
■ 44-3445/M	616314178306	01616314178305	02616314178304
■ 44-3445/L	616314178290	01616314178299	02616314178298
■ 44-3445/XL	616314178320	01616314178329	02616314178328
■ 44-3445/XXL	616314178344	01616314178343	02616314178342

DIMENSIONS (in/cm)

	XS	S	M	L	XL	XXL
A	20.5 / 8.07	21.5 / 8.46	22.5 / 8.86	9.25 / 23.5	9.65 / 24.5	9.84 / 25
B	3.3 / 8.5	3.4 / 8.7	3.9 / 10	4.1 / 10.3	4.2 / 10.6	4.3 / 10.8
H	■ Blue	□ White	■ Green	■ Brown	■ Yellow	■ Gray

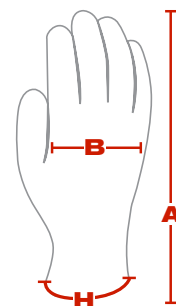

PROTECTIVE INDUSTRIAL PRODUCTS, INC. | BRINGING THE BEST OF THE WORLD TO YOU®

AMERICAS: (800) 262-5755 • (518) 861-0133 | EUROPE: +34-96182-41-48 | AMEA: (ASIA, MIDDLE EAST, AFRICA) 852-2475-9228 | www.pipglobal.com

This document and the information contained herein is the property of Protective Industrial Products, Inc. (PIP) and may not be used or reproduced without permission. Product users should conduct all appropriate testing or other evaluations to determine the suitability of PIP products for a particular purpose or use within a particular environment. PIP DISCLAIMS ALL WARRANTIES OTHER THAN AS EXPRESSLY PROVIDED.