



**PROTECTIVE INDUSTRIAL PRODUCTS**

# 48-L185T Specification Sheet

## UNSUPPORTED LATEX GLOVES

### PRODUCT DESCRIPTION:

Unsupported latex, 18 mil, 12-inch flock lined, yellow, honeycomb grip, beaded rolled cuff.

- Rolled bead cuff for tear resistance
- Flock lining provides increased comfort and ease of donning

### Applications:

Ideal for janitorial, sanitation and general maintenance.

### TECHNICAL DATA:

**Material:** Natural rubber latex; cotton

**Color:** Orange

**Cuff Style:** Beaded rolled

**Available Sizes:** S - XXL

**Packaging:** 12 per dozen; 12 dozen per case

**Case Dimensions (cm):** 32 x 27.6 x 33.0 / (in): 12.6 x 10.9 x 13.0

**Case Weight:** (S) 20.9 lbs / 9.5 kg (XL) 27.7 lbs / 12.6 kg

(M) 23.5 lbs / 10.7 kg (XXL) 27.7 lbs / 12.6 kg

(L) 25.0 lbs / 11.3 kg

**Manufacturer Certifications:** ISO9001:2000 certified

**Country of Origin/Harmonization Code:** Malaysia/4015.19.1050

### Laundering Instructions:


It is strongly advised not to wash and re-use these gloves when they are used to protect against chemical products.



### DIMENSIONS:

Size Available	<u>S</u>	<u>M</u>	<u>L</u>	<u>XL</u>	<u>XXL</u>
Over Length (cm) +/-1cm -A (in)	30.5 12.0	30.5 12.0	30.5 12.0	30.5 12.0	30.5 12.0
Palm Width (cm) +/-1cm -B (in)	9.0 3.5	10.0 3.9	10.8 4.3	11.6 4.6	13.0 5.1
Palm Thickness	0.45 mm				
Cuff Thickness	0.40 mm				
Finger Tip Thickness	0.48 mm				

BARCODE #	DOZEN	CASE
48-L185T/XXL	01616314038242	02616314038242
48-L185T/XL	01616314034954	02616314034954
48-L185T/L	01616314034923	02616314034923
48-L185T/M	01616314034930	02616314034930
48-L185T/S	01616314034947	02616314034947

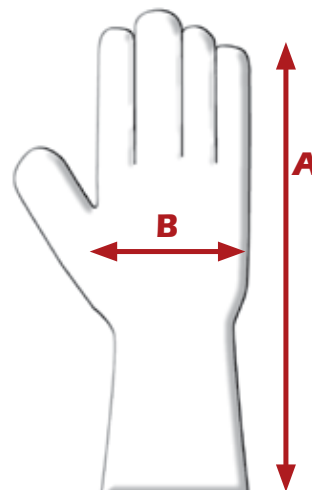

CAUTION: This style contains natural rubber latex which may cause allergic reactions. Safe use by or on latex-sensitive individuals has not been established.  
This document is the property of PIP and the information contained herein is proprietary to PIP.