



**PROTECTIVE INDUSTRIAL PRODUCTS**

# 52-3672 Specification Sheet

## UNSUPPORTED NEOPRENE GLOVES

### PRODUCT DESCRIPTION:

19 mil., blue neoprene over yellow latex, double dipped, flock lined, raised diamond grip, 12 in , dozen packed.

- Neoprene gloves provide superior protection from a wide range of chemicals such as acids, caustics, solvents and oils;
- Raised diamond grip;
- Flock lined;
- Double dipped style provides versatile chemical resistance properties of neoprene and the comfort of latex.

### Applications:

Ideal for use in the petrochemical industry, janitorial and general maintenance and photo finishing.

### TECHNICAL DATA:

**Material:** Neoprene, natural rubber latex

**Color:** Blue & yellow

**Cuff Style:** Straight cuff

**Available Sizes:** S - XL

**Packaging:** 12 per dozen; 12 dozen per case

**Case Dimensions (cm):** 38 x 35 x 31 / (in): 18.5 x 14.2 x 13.0

**Case Weight:** (S) 26.5 lbs / 12.0 kg (L) 28.2 lbs / 12.8 kg  
(M) 27.3 lbs / 12.4 kg (XL) 29.5 lbs / 13.4 kg

**Manufacturer Certifications:** ISO 9001: 2000

**Country of Origin/Harmonization Code:** Malaysia/4015.19.1050

### PERFORMANCE PROPERTIES:

EN388: 1011

Abrasion = 1; Cut = 0; Tear = 1; Puncture = 1

### Elongation Information:

| Before Aging               |                      | After Accelerated Aging    |                      |
|----------------------------|----------------------|----------------------------|----------------------|
| Tensile Strength (minimum) | Elongation (minimum) | Tensile Strength (minimum) | Elongation (minimum) |
| (Mpa)                      | %                    | (Mpa)                      | %                    |
| 15                         | 600                  | 10                         | 500                  |

### BARCODE #

### DOZEN

### CASE


|            |                |                |
|------------|----------------|----------------|
| 52-3672/XL | 01616314011122 | 02616314011122 |
| 52-3672/L  | 01616314011115 | 02616314011115 |
| 52-3672/M  | 01616314011108 | 02616314011108 |
| 52-3672/S  | 01616314011092 | 02616314011092 |



### DIMENSIONS:

| Size Available                     | S            | M            | L            | XL           |
|------------------------------------|--------------|--------------|--------------|--------------|
| Over Length (cm) +/-1cm -A<br>(in) | 32.0<br>12.6 | 32.0<br>12.6 | 32.0<br>12.6 | 32.0<br>12.6 |
| Palm Width (cm) +/-1cm -B<br>(in)  | 10.0<br>3.9  | 10.9<br>4.3  | 11.2<br>4.4  | 11.6<br>4.6  |

|                      |         |
|----------------------|---------|
| Palm Thickness       | 0.52 mm |
| Cuff Thickness       | 0.44 mm |
| Finger Tip Thickness | 0.70 mm |

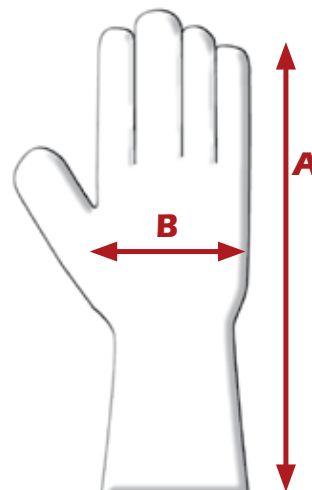

CAUTION: This style contains natural rubber latex which may cause allergic reactions. Safe use by or on latex-sensitive individuals has not been established.  
This document is the property of PIP and the information contained herein is proprietary to PIP.