



PROTECTIVE INDUSTRIAL PRODUCTS

63-338PF Specification Sheet

DISPOSABLE NITRILE

PRODUCT DESCRIPTION:

Nitrile gloves, industrial grade, powder-free, 8 mil, textured grip.

- Made from component materials which comply with Federal regulations for food contact. 21CFR, 170-199;
- Contains no natural rubber latex proteins;
- Ambidextrous;
- Economical puncture resistance with great comfort, dexterity and tactile sensitivity;
- Silicone free.

Applications:

A very versatile glove for use in a broad range of applications for light hand protection from liquids, chemicals and debris.

TECHNICAL DATA:

Material: Nitrile

Color: Blue

Available Sizes: S - XL

Packaging: 50 pcs per inner; 20 inner per carton (1,000 pcs)

Case Dimensions (cm): 63.5 X 24.9 X 28.0

(in): 10.4 x 10.0 x 14.5

Case Weight: (S) 16.0 lbs / 7.3 kg (L) 26.0 lbs / 11.8 kg

(M) 25.0 lbs / 11.3 kg (XL) 27.0 lbs / 12.2 kg

AQL Level: 4.0

Manufacturer Certifications: ISO 9002 certified

Country of Origin/Harmonization Code: Malaysia/4015.19.1010



DIMENSIONS:

Size Available	S	M	L	XL
Over Length (cm) ± 0.5 - A (in)	25.0 9.8	25.0 9.8	25.0 9.8	25.0 9.8
Palm Width (cm) ± 0.5 - B (in)	8.7 3.4	9.4 3.7	10.7 4.2	11.2 4.4


Palm Thickness	0.20 (+/- 0.02) mm
Cuff Thickness	0.13 (+/- 0.02) mm
Finger Tip Thickness	0.22 (+/- 0.02) mm

ELONGATION INFORMATION:

Before Aging		After Accelerated Aging	
Tensile Strength (minimum)	Elongation (minimum)	Tensile Strength (minimum)	Elongation (minimum)
(Mpa)	%	(Mpa)	%
14.0	600	14.0	500

BARCODE # DISPENSER BOX CASE

63-338PF/XL	616314011368	02616314011368
63-338PF/L	616314011351	02616314011351
63-338PF/M	616314011344	02616314011344
63-338PF/S	616314011337	02616314011337

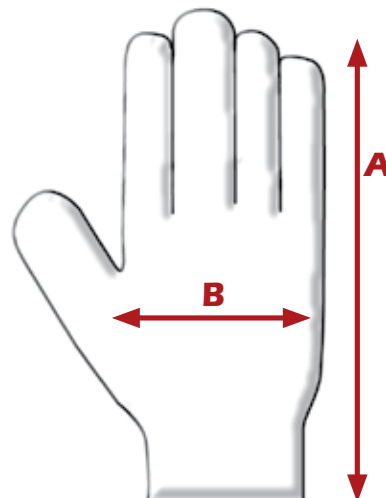

This document is the property of PIP and the information contained herein is proprietary to PIP.