



PROTECTIVE INDUSTRIAL PRODUCTS

64-435PF Specification Sheet

DISPOSABLE VINYL

PRODUCT DESCRIPTION:

Powder free clear vinyl glove, exam grade, 9.5-inch length, AQL 1.5.

- Made from a soft-vgin vinyl formulation specially compounded to deliver an optimal combination of comfort, fit, flexibility, tactile sensitivity and performance;
- Made from component materials which comply with Federal Regulations for food contact. 21CFR, 170-199;
- Synthetic polymer coating for ease of donning and doffing;
- Physical properties meet or exceed ASTM requirements for vinyl gloves;
- Contains NO natural rubber latex proteins;
- DEHP & DOP free.
- Accelerator free

Applications:

Ideal for food handling & processing, pharmaceuticals, laboratories to avoid concerns regarding latex proteins.

TECHNICAL DATA:

Material: Vinyl

Color: Translucent white

Cuff Style: Rolled beaded

Available Sizes: S - XL

Packaging: 100 gloves per dispenser box, 10 boxes per case

Case Dimensions (cm): 26.5 X 25.5 X 36.8

(in): 10.4 X 10.0 X 14.5

Case Weight: (S) 14.3 lbs / 6.5 kg (L) 16.5 lbs / 7.5 kg

(M) 15.4 lbs / 7.0 kg (XL) 17.6 lbs / 8.0 kg

AQL Level: 1.5

Manufacturer Certifications: ISO13485:2003; ISO9001:2000 certified

Country of Origin/Harmonization Code: China/3926.20.1010



DIMENSIONS:


Size Available	<u>S</u>	<u>M</u>	<u>L</u>	<u>XL</u>
Over Length (cm)-A (in)	24.0 9.4	24.0 9.4	24.0 9.4	24.0 9.4
Palm Width (cm)(+/-0.5)-B (in)	8.5 3.3	9.5 3.7	10.5 4.1	11.5 4.5
Palm Thickness	0.08 mm			
Cuff Thickness	0.06 mm			
Finger Tip Thickness	0.07 mm			

ELONGATION INFORMATION:

Before Aging		After Accelerated Aging	
Tensile Strength (minimum)	Elongation (minimum)	Tensile Strength (minimum)	Elongation (minimum)
(Mpa)	%	(Mpa)	%
13	400	13	400

BARCODE # DISPENSER BOX CASE

64-435PF/XL	616314005237	02616314005237
64-435PF/L	616314005220	02616314005220
64-435PF/M	616314005213	02616314005213
64-435PF/S	616314005206	02616314005206

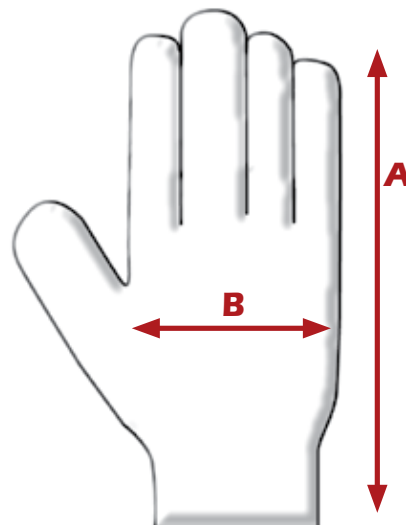

This document is the property of PIP and the information contained herein is proprietary to PIP.