



SPECIFICATION SHEET

67-246

AMBI-DEX® GRIPPАЗ™ SKINS SUPERIOR AMBIDEXTROUS NITRILE GLOVE WITH TEXTURED FISH SCALE GRIP - 6 MIL

- Patented fish scale design on the inside and outside of glove provides extra traction with oily or wet parts
- Rotated thumb grip for secure precision grip of small parts
- 100% nitrile provides resistant to many chemicals used in industrial applications
- Amplified dexterity for enhanced comfort mobility and less hand fatigue
- Increased puncture resistance outlasts conventional disposables which helps reduce waste
- Form-fitting beaded cuff can be worn over a liner
- Powder-Free to reduce allergic reactions
- Made from component materials that comply with Federal Regulations for food contact 21 CFR, 170-199

APPLICATIONS

- Mechanics
- Engineering
- Agriculture
- General Use

TECHNICAL DATA

| | | | | | |
|-----------------|--------------------------------------------------|-------------------|-------------------|--------------------|--------------------|
| MATERIAL | 100% Nitrile (no latex) | | | | |
| THICKNESS | 6 mil (10 mil at grip) | | | | |
| COLOR | ■ Black | | | | |
| CUFF STYLE | Beaded | | | | |
| SIZES | S - XXL | | | | |
| PACKAGING | 50 gloves per box / 10 boxes per case | | | | |
| CASE DIMENSIONS | 10.4" x 10.5" x 10.2" / 26.5cm x 26.6cm x 25.8cm | | | | |
| CASE WEIGHT | S | M | L | XL | XXL |
| | 8.6 lbs 3.9 kg | 9.3 lbs 4.2 kg | 9.9 lbs 4.5 kg | 10.6 lbs 4.8 kg | 11.2 lbs 5.1 kg |
| COO | Malaysia | | | | |

ELONGATION INFORMATION

| BEFORE AGING | | AFTER ACCELERATED AGING | |
|----------------------------|----------------------|----------------------------|----------------------|
| Tensile Strength (minimum) | Elongation (minimum) | Tensile Strength (minimum) | Elongation (minimum) |
| (Mpa) | % | (Mpa) | % |
| 14 | 500 | 14 | 400 |


BARCODES

| ITEM | BOX | DOZEN | CASE |
|--------------|--------------|-------|----------------|
| ■ 67-246/S | 616314221873 | --- | 02616314221871 |
| ■ 67-246/M | 616314221866 | --- | 02616314221864 |
| ■ 67-246/L | 616314221859 | --- | 02616314221857 |
| ■ 67-246/XL | 616314221880 | --- | 02616314221888 |
| ■ 67-246/XXL | 616314221897 | --- | 02616314221895 |



DIMENSIONS (in/cm)

| | S | M | L | XL | XXL |
|----------|-----------|-----------|------------|------------|------------|
| A | 9.5 / 24 | 9.5 / 24 | 9.5 / 24 | 9.5 / 24 | 9.5 / 24 |
| B | 3.3 / 8.5 | 3.7 / 9.5 | 4.1 / 10.5 | 4.5 / 11.5 | 4.8 / 12.3 |

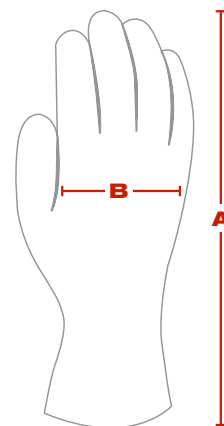

PROTECTIVE INDUSTRIAL PRODUCTS, INC. | BRINGING THE BEST OF THE WORLD TO YOU®

AMERICAS: (800) 262-5755 • (518) 861-0133 | EUROPE: +34-96182-41-48 | AMEA: (ASIA, MIDDLE EAST, AFRICA) 852-2475-9228 | www.pipglobal.com

This document and the information contained herein is the property of Protective Industrial Products, Inc. (PIP) and may not be used or reproduced without permission. Product users should conduct all appropriate testing or other evaluations to determine the suitability of PIP products for a particular purpose or use within a particular environment. PIP DISCLAIMS ALL WARRANTIES OTHER THAN AS EXPRESSLY PROVIDED.