



SPECIFICATION SHEET

9100-2110D



8.5 cal/cm² DUAL CERTIFIED, INSECT REPELLANT COVERALL

- HRC2, ATPV 8.5 cal/cm²
- NFPA 2112-2012
- UL Certified
- Aramid high tenacity FR thread
- No metal pieces on the garment
- Bar-tacked at all stress points
- Protective stand-up collar with hook & loop closure
- Storm guard with hook & loop closure
- Action back for mobility
- Side elasticized waist
- FR rib knit cuffs
- Hook & loop on bottom
- 2 waist patch pockets with side access

STANDARDS MET

- NFPA 1975-2009, NFPA 2112-2012
- NFPA 70E 2012, ASTM F 1506-2010a
- CAN/CGSB 155.20-2000, CAN/CGSB 155.22-97
- OSHA 29 CFR 1910.269
- EN ISO 11611:2008, EN ISO 11612:2008, EN ISO 14116:2008
- UL Model # STC24

APPLICATIONS

- Electrical & Utilities
- Petrochemical, Gas & Oil
- Mining
- Welding
- Emergency Services

CARE INSTRUCTIONS

Machine wash warm, 165° F max. Tumble dry low. DO NOT bleach.
DO NOT use fabric softener. DO NOT iron. DO NOT Dry clean.


TECHNICAL DATA

MATERIAL	FR & bug repellant twill weave. 90% Cotton/10% Nylon
CONSTRUCTION	7oz FR & insect repellant* twill weave. 90% Cotton/10% Nylon.
COLOR	■ Khaki (9100-2110D)
SIZES	S - 5X
PACKAGING	1/Polybag, 18/Case
CASE	22" x 16" x 16" / 56cm x 41cm x 41cm
CASE WEIGHT	53 lbs / 24 kg
COO	China
HARM CODE	6211.32.0010

*Permethrin Impregnated Material

BARCODES

ITEM	BAG	BOX	CASE
■ 9100-2110D/S	616314151071	---	02616314151079
■ 9100-2110D/M	616314151088	---	02616314151086
■ 9100-2110D/L	616314151095	---	02616314151093
■ 9100-2110D/XL	616314151101	---	02616314151109
■ 9100-2110D/2X	616314151118	---	02616314151116
■ 9100-2110D/3X	616314151125	---	02616314151123
■ 9100-2110D/4X	616314151132	---	02616314151130
■ 9100-2110D/5X	616314151149	---	02616314151147

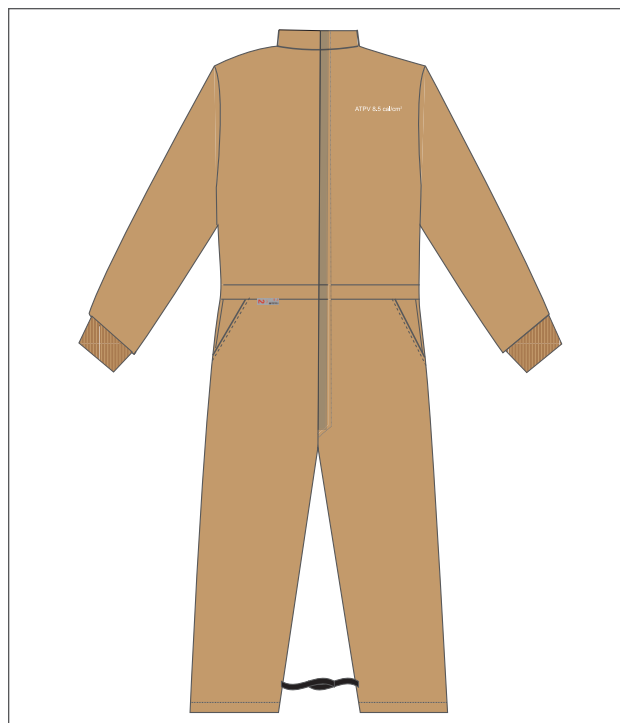

DIMENSIONS (in)

	S	M	L	XL	2X	3X	4X	5X
A	36-38	40-42	44-46	48-50	52-54	56-58	60-62	64-66
B	32-34	36-38	40-42	44-46	48-50	52-54	56-58	60-62
C	34.5	35.5	36.5	38	39.5	41	42.5	44
D	32	32	32	32	32	32	32	32

