

CV-7667K(W)

D/N Varifocal IR Vandal-proof Dome

FEATURES

- ★ 1/3" SONY IMX138 1.3MP CMOS
- ★ 1000 TVL (720p) High Resolution
- ★ 2.8~12mm Varifocal Lens
- ★ 36 IR LEDs and 100ft IR Range
- ★ IR-Cut Filter
- ★ White Color Available (CV-7667KW)
- ★ Multi-Axis for Wall or Ceiling Mounting
- ★ Weatherproof: IP66
- ★ DC 12V




SPECIFICATION

MODEL	CV-7667K(W)
Image Sensor	1/3" SONY IMX138 1.3MP CMOS
Effective Pixels	NTSC: 960(H) x 480(V)
Scanning System	2:1 Interlaced
Sync. System	Internal
Horizontal Resolution	1000 TV Lines (720P)
Lens	2.8~12 mm Varifocal Lens
OSD Menu	Built-in
White Balance	AWB-PRO / AWB-TEMPORA AWB-AI / AWB-GW / AWB-CCT
BLC	ON / OFF / AUTO
NR	3D Noise Reduction
Mirror Function	OM / OFF
Image Adjustment	Contrast / Sharpness / Saturation
Motion Detection	OFF / ON (4 Areas)
Privacy Zones	OFF / ON (8 Areas)
Day & Night	AUTO / B/W / Exton / Color
S/N Ratio	More than 50dB (AGC OFF)
Electronic Shutter	AUTO
Video Output	1.0V p-p Composite output, 75Ω
IR Range	100ft (30m) IR Range w/ 36 IR LEDs
Mini Illumination	0 Lux / F1.2 (with IR on)
Power	DC 12V ± 10% (500mA)
Operation Temp	14°F ~ 122°F (-10°C ~ 50°C)
Dimensions	4.65" (W) x 3.35" (H) (118mm (W) x 85mm (H))
Weight (g)	1.81lb (820g)

JUNCTION BOX (OPTIONAL)

JC666

- ① Self-adhesive sticker
- ② cable tie
- ③ Connection plate
- ④ Stopper
- ⑤ Wall screws
- ⑥ Foam pad
- ⑦ Round head screws

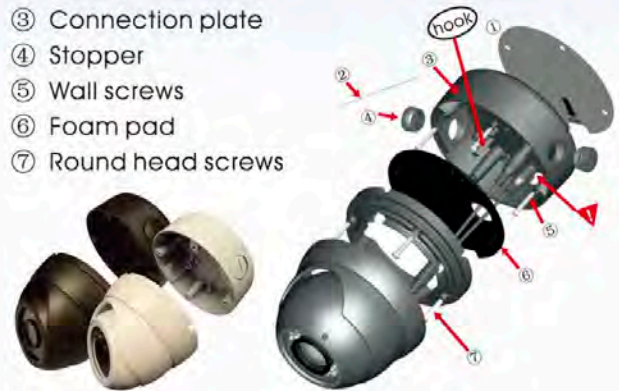

EXTERNAL DIMENSIONS

