

GV-VD2500 2MP H.264 Super Low Lux WDR IR Vandal Proof IP Dome




- 1/2.8" progressive scan super low lux CMOS
- Min. illumination at 0.02 lux
- Dual streams from H.264 and MJPEG
- Up to 30 fps at 1920 x 1080
- Vandal resistance (IK10+)
- Ingress protection (IP67)
- Varifocal megapixel lens
- 3-axis mechanism (pan / tilt / roll)
- Day/Night function (with removable IR-cut filter)
- External microphone
- Intelligent IR
- IR distance up to 30 m (98.4 ft)
- Two-way audio
- One sensor input and alarm output
- TV-out support
- Built-in micro SD card slot (SD/SDHC) for local storage
- Recording assigned by GV-Edge Recording Manager ([Windows](#), [Mac](#) version)
- DC 12V / AC 24V / PoE (IEEE 802.3af)
- Wide Dynamic Range (WDR)
- 3D DNR (Digital Noise Reduction)
- Defog
- Motion detection
- Tampering alarm
- Privacy mask
- IP address filtering
- Supports iPhone, iPad, Android & 3GPP
- 31 languages on Web interface
- ONVIF (Profile S) conformant
- More storage option – [NAS](#)

*No Memory card slot & local storage function for Argentina.

Active Tampering Alarm


Tampered

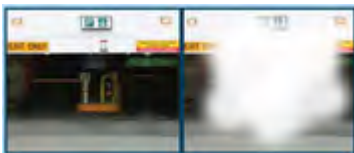

Focus Change



Camera Shift

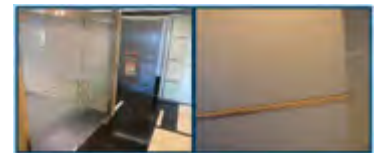

Introduction

The GV-VD2500 is an outdoor camera (IP67) designed with vandal protection (IK10+). The camera is capable of providing a color live view in near darkness using its super low lux CMOS image sensor. The camera also supports various installations, including wall surface, wall corner, pole and ceiling using the GV-Mount accessories (optional).