


170-20800

HellermannTyton

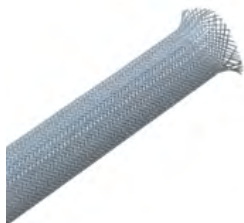

Article Number: 170-20800

Description: Helagaine Braided Sleeve, 8 mm Dia, PA66, GY, 328ft/Reel

Base Data		
	Local Order Number	170-20800
	Type	HEGPA6608
	Color	Gray (GY)
	Features and benefits	- Nylon monofilament construction weave offers a tight braid that provides full coverage but will not rot or retain moisture. - Material performs well in wet applications and where abiding substrate has a smooth surface.
	Quantity Per	metre
	Product Description	Helagaine Nylon Polyamide Expandable Braided Sleeve is a pliable yet durable sleeve that protects against cuts, abrasion and excessive wear caused by repetitive motion.
	Short Description	Helagaine Braided Sleeve, 8 mm Dia, PA66, GY, 328ft/Reel
Product Dimensions		
	Length L (Imperial)	328.0ft
	Length L (Metric)	100.0m
	Reel Length (imperial)	328.0ft
	Bundle Diameter Min. (Imperial)	0.2"
	Bundle Diameter Min. (Metric)	5mm
	Bundle Diameter Max. (Imperial)	0.4"
	Bundle Diameter Max. (Metric)	10mm
	Diameter D (imperial)	0.31"
	Nominal Diameter (Imperial)	5/16"
	Nominal Diameter (Metric)	8mm
Material and Specifications		
	Material	Polyamide 6.6 (PA66)
	Material Shortcut	PA66

170-20800



Material and Specifications	Flammability	UL 94 V2
	Halogenfree	Yes
	Operating Temperature	-76°F to +302°F (-60°C to +150°C)
	REACH Compliant (Article 33)	Yes
	ROHS Compliant	Yes
	Certification/Specification	EN [45545-2]:2013
Logistic and Packaging		
	Package Quantity (Imperial)	328ft
	Package Quantity (Metric)	100m
	Customs Number(Schedule B)	3926909987
	Content Unit (BMEcat)	metre
	Weight (Metric)	0.5kg