


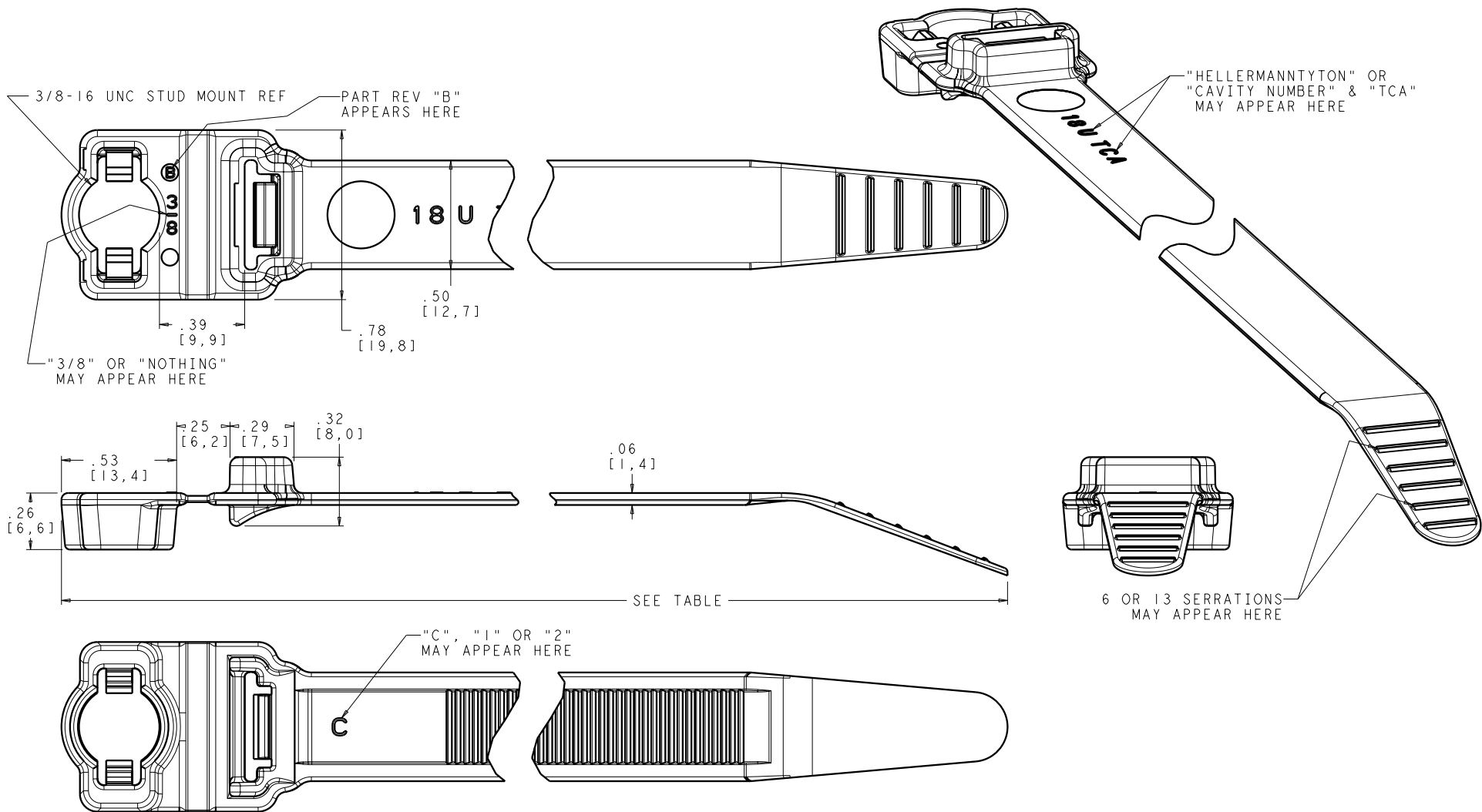

- △04 PERFORMANCE REQUIREMENTS (Dry as Molded):**
1. STRAP INSERTION < 5 lb.
 2. MINIMUM WIRE BUNDLE DIAMETER = 3/8"
 3. LOOP TENSILE > 120 lb.
 4. STUD INSERTION < 10 lb.
 5. STUD PULLOUT > 110 lb.

PART NUMBER	OVERALL LENGTH	MAX BUNDLE DIA
WSS380	9.7	2.25
WSI380	12.7	3.25
WSR380	15.7	4.125

IN
V
E
N
T
O
R
S

HellermannTyton®

ALL PROPRIETARY RIGHTS IN THE SUBJECT MATTER SHOWN ON THIS DRAWING ARE EXCLUSIVE PROPERTY OF HELLERMANN TYTON

name	date	city, state
G GEIGER	3/17/03	JACKSON, WI

RE
V
I
S
I
O
N

level	△04
by	GGG
date	11/25/09
ECN #	011439
part level	B

D
I
M
E
N
S
I
O
N
S

.XXXX= ±0.005/[1,127]
.XXX= ±0.010/[1,25]
.XX= ±0.02/[1,5]
.X= ±0.25/[6,4]
∠= ±0.5
unless otherwise specified
units inches/[mm]

P
A
R
T

number	see table	phase	△04 PRODUCTION
name	T120 WIDE STRAP W/ 3/8" STUD MOUNT		
material	IMPACT MODIFIED, HEAT STABILIZED UV RESISTANT, NYLON 6/6 BLACK		

D
R
A
W
I
N
G

FORMAT AH version J	CAD	PRO-E	scale 3/2
computer file number	previous number		
drawn	G GEIGER	checked	K Christian
date	8/29/02	checked	11/25/09
type	CUSTOMER		approved
number	CT2127010CST		
			sheet 1 of 1