

DS-2CD2332-I


3 MP EXIR Turret Network Camera



Key Features

- Full HD1080p Real-Time Video
- 3 Megapixel (2048 x 1536) Resolution
- DWDR, 3D DNR, and BLC
- EXIR Illuminator (Up to 30 Meters Range)
- IP66
- PoE

Dimensions

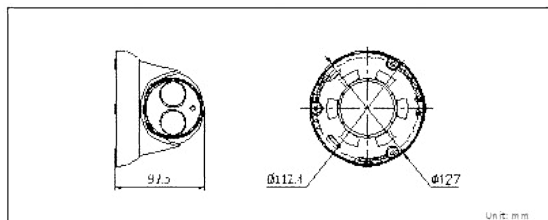

Accessories



DS-1239ZJ-1

Wall Mount
Aluminium Bracket
(with junction box)

DS-2CD2332-I	
Camera	
Image Sensor	1/3" progressive scan CMOS
Minimum Illumination	0.19 lux @ f/2.0, AGC on; 0 lux with IR
Shutter Speed	1/30 s to 1/100,000 s
Lens	4 mm @ f/2.0, angle of view: 75.8° (2.8 mm, 6 mm, 12 mm optional)
Lens Mount	M12
Angle Adjustment	Pan: 0° to 360°, tilt: 0° to 75°, rotation: 0° to 360°
Day/Night	ICR
Digital Noise Reduction	3D DNR
Wide Dynamic Range	Digital WDR
Backlight Compensation	Yes, zone configurable
Compression Standard	
Video Compression	H.264/MJPEG
H.264 Compression Profile	Main profile
Bit Rate	32 Kbps to 16 Mbps
Dual Stream	Yes
Image	
Maximum Image Resolution	2048 x 1536
Frame Rate	60 Hz: 15 fps (2048 × 1536), 30 fps (1920 × 1080), 30 fps (1280 × 720)
Image Settings	Saturation, brightness, contrast adjustable through client software or Web browser
Network	
Network Storage	NAS
Alarm Trigger	Motion detection, tampering alarm
Protocols	TCP/IP, HTTP, DHCP, DNS, DDNS, RTP, RTSP, PPPoE, SMTP, NTP, SNMP, HTTPS, FTP, 802.1X, QoS
System Compatibility	ONVIF, PSIA, CGI, ISAPI
General Functionalities	User authentication, watermark
Interface	
Communication Interface	1 RJ-45 10M/100M Ethernet port
General	
Operating Conditions	-30° C to 60° C (-22° F to 140° F); humidity 95% or less (non-condensing)
Power	12 VDC ±10%, PoE (802.3af)
Power Consumption	Maximum 5.5 W (7.5 W with ICR on)
Ingress Protection	IP66
EXIR Range	Up to 30 meters
Dimensions	Φ127 mm x 97.5 mm
Weight	670 g (1.5 lbs)

Order Models

DS-2CD2332-I