


960H Indoor Dome Camera with Built-In IR LEDs

- CLED32D7B** 3.6mm fixed lens, black housing
- CLED32D7W** 3.6mm fixed lens, white housing
- CLED32D1B** 2.8-12mm auto iris varifocal lens, black housing
- CLED32D1W** 2.8-12mm auto iris varifocal lens, white housing

Features

- 700 TV lines of resolution
- IR Range: 65'
- 3-axis design, both wall and ceiling mountable
- 12VDC operation
- 5 year warranty

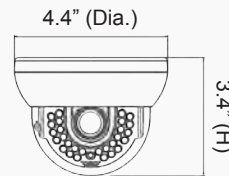

Specifications

Image Sensor 1/3" color 960H CCD
 Resolution..... 700 TV lines
 Minimum Illumination..... 0 lux with IR on
 S/N Ratio 50dB
 Effective Pixels 976 (H) x 494 (V)
 Total Pixels 1020 (H) x 508 (V)
 Shutter 1/60 sec. – 1/120,000 sec.
 Number of IR LEDs 24
 IR Range 65 ft. (depending on scene reflection)
 Synchronization Internal
 DNR..... Low
 White Balance ATW
 TV System NTSC
 Housing High impact ABS
 Operating Temperature.. 14° F - 122° F
 Power Supply 12VDC (power supply not included)
 Power Consumption 250mA
 Dimensions..... 4.4" (Dia.) x 3.4" (H)
 Weight 8 oz.
 Included in Package Main unit, mounting screws, test monitor lead,
 DC lead, user manual

Optional Accessory



PSW5
12VDC
Power Supply

