


Supervised Horns & Cluster Speakers

Cluster with RSS Strobe



Available with 2, 3 or 4 STH-15S horns

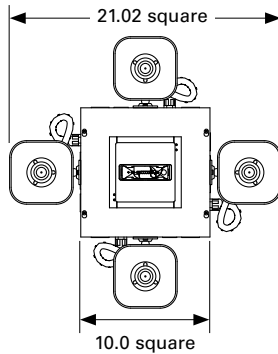

Series **STH** Cluster with RSS Strobe

Available features and options:

Supervised Speaker Strobe supplied with 2, 3, or 4 STH-15SR horns and one RSS-24MCCH ceiling strobe (red, white, no lettering) mounted to a NEMA 1 steel enclosure

Finish Color: Red

Mounting: Wall, Ceiling or Roof

Size: Prefabricated 10" x 10" x 6" fiberglass enclosure

Sensitivity: 102 dB @ 15 watts @ 10 ft. per horn

Strobe Candela: High Intensity, Selectable 115/177

Approvals: UL Standard 1480 (Horns), UL 1971 (RSS Strobes), UL Standard 1638 (Colored Lens Strobes)

STH Cluster with RSS Strobe

Model Number	Finish	Order Code
4 Horns		
STH-4R24MCCH-FR	Red	3090
STH-4R24MCCH-NR	Red (no ltr)	3089
STH-4R24MCCH-FW	White	0235
STH-4R24MCCH-NW	White (no ltr)	0239
3 Horns		
STH-3R24MCCH-FR	Red	3145
STH-3R24MCCH-NR	Red (no ltr)	3144
STH-3R24MCCH-FW	White	0234
STH-3R24MCCH-NW	White (no ltr)	0238
2 Horn		
STH-2R24MCCH-FR	Red	3143
STH-2R24MCCH-NR	Red (no ltr)	3146
4 Horn		
STH-90-R24MCCH-FR	Red	0522
STH-90-R24MCCH-NR	Red (no ltr)	3227

UL Max. Current

	115cd	177cd
24 VDC	0.300	0.420

Note: Reference pages 58-65 for additional mounting information.