


ZCKY59

limit switch lever ZCKY - th.plastic round rod lever
6 mm L=200 mm - -40..70°C

Product availability : Stock - Normally stocked in distribution facility



Price* : 8.50 USD

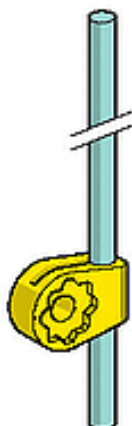

Main

Range of product	OsiSense XC
Series name	Standard format
Product or component type	Limit switch lever
Device short name	ZCKY
Product compatibility	XCKJ XCKL XCKM XCKS
Associated head	ZCKE05 ZCKD05
Movement of operating head	Rotary
Type of operator	Rod lever spring return thermoplastic (round rod 6 mm, L = 200 mm)
Type of approach	Lateral approach

Complementary

Switch actuation	By any moving part
Positive opening	Without

Environment

Ambient air temperature for operation	-40...158 °F (-40...70 °C) low temperature -13...158 °F (-25...70 °C) standard environment
Ambient air temperature for storage	-40...158 °F (-40...70 °C) low temperature -40...158 °F (-40...70 °C) standard environment
Environmental characteristic	Standard environment Low temperature

Ordering and shipping details

Category	22411 - LIMIT SWITCHES,IEC,XCKJ
Discount Schedule	T
GTIN	00785901646419
Nbr. of units in pkg.	1
Package weight(Lbs)	5.999999999999998E-2
Returnability	Y
Country of origin	ID

Offer Sustainability

Sustainable offer status	Green Premium product
RoHS (date code: YYWW)	Compliant - since 1005 - Schneider Electric declaration of conformity Schneider Electric declaration of conformity
REACH	Reference not containing SVHC above the threshold Reference not containing SVHC above the threshold
Product end of life instructions	Need no specific recycling operations

Contractual warranty

Warranty period	18 months
-----------------	-----------