


Wall Taps and Wall Plates

VersaTap Series



Front Figures

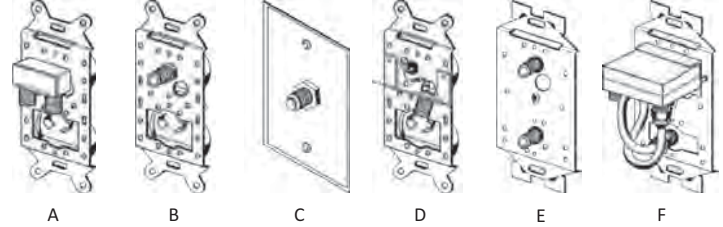

Back Figures

Specifications

	V-2WS	V-3889		V-1GF-FT	V-ST	V-2GF-FT	TF-GF-FT	V-3164
Front Figure:	2	1	Front Figure:	1	1	2	3	4
Back Figure:	F	A	Back Figure:	B	D	E	C	
Number of Outputs:	1	2	Number of Outputs:	1	1	2	1	
Impedance (Ω):	75	75	Impedance:	75	75	75	75	
Frequency Band:	SUB/VHF/ CATV/UHF	SUB/VHF/ CATV/UHF	Frequency Band:	SUB/VHF CATV/UHF	SUB/VHF/UHF	SUB/VHF CATV/UHF Remote Control	SUB/VHF UHF/CATV/FM	
Connector(s):	"F"	"F"	Connector:	"G/F"	"G"	"G/F"	"G/F"	N/A
RF Isolation (dB) Available:	4	6 9 12 16 20 24 27 30						
Thru loss (dB)								
SUB:	3.5	3.0 1.2 0.9 0.7 0.6 0.5 0.5 0.5						
VHF:	3.5	3.0 1.2 0.9 0.7 0.6 0.5 0.5 0.5						
UHF:	4.0	3.5 1.6 1.5 0.7 0.7 0.6 0.6 0.6						
Special Characteristics			Special Characteristics					
RFI Shielded Circuitry	X	X	RFI Shielded Circuitry	X		X	X	
Other	2-Port Terminating		Other		Self terminating			Single gang frame with blank filler plate ivory plastic

Features & Benefits

- Steel Backplate for Mechanical Strength
- Ivory Plastic Front Plate

Blonder Tongue's VersaTap Series is the most complete and mechanically robust line of MATV and CATV wall taps and plates available. These products are manufactured using steel back plates with ivory plastic front filler plates (except TF-GF-FT). RFI shielded models are available.

Ordering Information

Model	Stock No.	Description
TF-GF-FT	4691	VersaTap Feed-Thru, Type "GF-81C", 75 Ω
V-1GF-FT	3187	VersaTap Feed-Thru, Type "GF-81C", 75 Ω
V-2GF-FT	3190	VersaTap Feed-Thru, 2 Type "GF-81C", 75 Ω
V-2WS	3191	VersaTap 2 Type "F", 75 Ω
V-3164	3164	VersaTap Blank Wall Plate
V-3889	3889	VersaTap 1 Tap Output, 75 Ω, Values: 4, 6, 9, 12, 16, 20, 24, 27, 30 dB
V-ST	3184	VersaTap Self-Terminating, Type "G", 75 Ω