



Building Entrance Terminal

OUTDOOR - 4000N SERIES - NEMA 4X



4000N Series - NEMA 4X

Building Entrance Terminal - Outdoor - NEMA 4X

Product Specifications

UL 497 Primary Protector for Communication Circuits

NAFTA Country of Origin: CANADA - All Loaded and Unloaded Models are "Buy America Act" Approved.

High Durability Fiberglass, Polycarbonate and Metal Construction
Suited for Corrosive and High Humidity Environments

Protects from Water, Dust, Dirt and Oil

Meets NEMA/EEMAC Type 4X Standards

Lockable Hinged Cover for Secure Access

Metal Backplate and Grommets Included

BET Pre-Installed from Factory

5 Pin Modules Sold Separately



Ordering Information

4050-110

Model Number	Stock Code	Pair Count	Input/Output	Material	Dimensions (H' x W" x D")	Weight (lbs)
4006-QC	904001	6	66/66	Polycarbonate	13.68 x 10.51 x 5.30	6.60
4006M-QC	904001M	6	66/66	Metal	14.00 x 10.00 x 6.18	18.00
4012-QC	904002	12	66/66	Polycarbonate	13.68 x 10.51 x 5.30	7.80
4012M-QC	904002M	12	66/66	Metal	14.00 x 10.00 x 6.18	19.00
4025-QC	904004	25	66/66	Polycarbonate	13.68 x 10.51 x 5.30	8.00
4025M-QC	904004M	25	66/66	Metal	14.00 x 10.00 x 6.18	19.50
4050-QC	904007	50	66/66	Fiberglass	16.27 x 14.40 x 8.13	13.50
4050M-QC	904007M	50	66/66	Metal	17.50 x 14.25 x 8.34	21.50
6-25PR Enclosure	UMM400010	EMPTY	EMPTY	Polycarbonate	13.68 x 10.51 x 5.30	6.00
6-25PRM Enclosure	UMM100017	EMPTY	EMPTY	Metal	14.00 x 10.00 x 6.18	14.00
50-100PR Enclosure	UMM100016	EMPTY	EMPTY	Fiberglass	16.27 x 14.40 x 8.13	5.50



Building Entrance Terminal

OUTDOOR - 4000N SERIES - NEMA 4X



Underwriters
Laboratories

4000N Series - NEMA 4X

Building Entrance Terminal - Outdoor - NEMA 4X

Ordering Information

Model Number	Stock Code	Pair Count	Input/Output	Material	Dimensions (H' x W" x D")	Weight (lbs)
4006-110	904000	6	110/110	Polycarbonate	13.68 x 10.51 x 5.30	6.60
4006M-110	90400M	6	110/110	Metal	14.00 x 10.00 x 6.18	18.00
4012-110	904008	12	110/110	Polycarbonate	13.68 x 10.51 x 5.30	7.70
4012M-110	904008M	12	110/110	Metal	14.00 x 10.00 x 6.18	19.00
4025-110	904003	25	110/110	Polycarbonate	13.68 x 10.51 x 5.30	11.00
4025M-110	904003M	25	110/110	Metal	14.00 x 10.00 x 6.18	19.50
4050-110	904005	50	110/110	Fiberglass	16.27 x 14.40 x 8.13	13.50
4050M-110	904005M	50	110/110	Metal	17.50 x 14.25 x 8.34	21.50
4100-110	904006	100	110/110	Fiberglass	16.27 x 14.40 x 8.13	23.00
4100M-110	904006M	100	110/110	Metal	17.50 x 14.25 x 8.34	31.00
4006-BIX	904010	6	BIX/BIX	Polycarbonate	13.68 x 10.51 x 5.30	7.00
4012-BIX	904011	12	BIX/BIX	Polycarbonate	13.68 x 10.51 x 5.30	7.00
4025-BIX	904012	25	BIX/BIX	Polycarbonate	13.68 x 10.51 x 5.30	9.00

4000N Series NEMA 4X - OUTDOOR BET - HIGH-SPEED DATA - CAT5e

4006-QCe	904001e	4 - 6	66/66	Polycarbonate	13.68 x 10.51 x 5.30	6.60
4012-QCe	904002e	12	66/66	Polycarbonate	13.68 x 10.51 x 5.30	7.80
4025-QCe	904004e	25	66/66	Polycarbonate	13.68 x 10.51 x 5.30	8.00
4006-110e	904000e	4 - 6	110/110	Polycarbonate	13.68 x 10.51 x 5.30	6.60
4012-110e	904008e	12	110/110	Polycarbonate	13.68 x 10.51 x 5.30	7.70
4025-110e	904003e	25	110/110	Polycarbonate	13.68 x 10.51 x 5.30	11.00
4006-BIXe	904016	4 - 6	BIX/BIX	Polycarbonate	13.68 x 10.51 x 5.30	7.00
4012-BIXe	904015	12	BIX/BIX	Polycarbonate	13.68 x 10.51 x 5.30	7.00
4025-BIXe	904014	25	BIX/BIX	Polycarbonate	13.68 x 10.51 x 5.30	9.00

Notes

Outdoor Wall Mount/Poll Mount (Poll Mount kit not included)

High Durability Fiberglass, Polycarbonate and Metal Construction Suited for Corrosive and High Humidity Environments

Meets NEMA/EEMAC Type 4X Standards

Previous Model Numbers: 30XXQC2P, 30XXBP, 3500 Series



Building Entrance Terminal

OUTDOOR - 4000N SERIES - NEMA 4X




Underwriters
Laboratories

Polycarbonate Enclosure

4 - 25 PAIR - OUTDOOR - NEMA 4X

Physical Dimensions

13.68 x 10.51 x 5.30
(H" x W" x D")

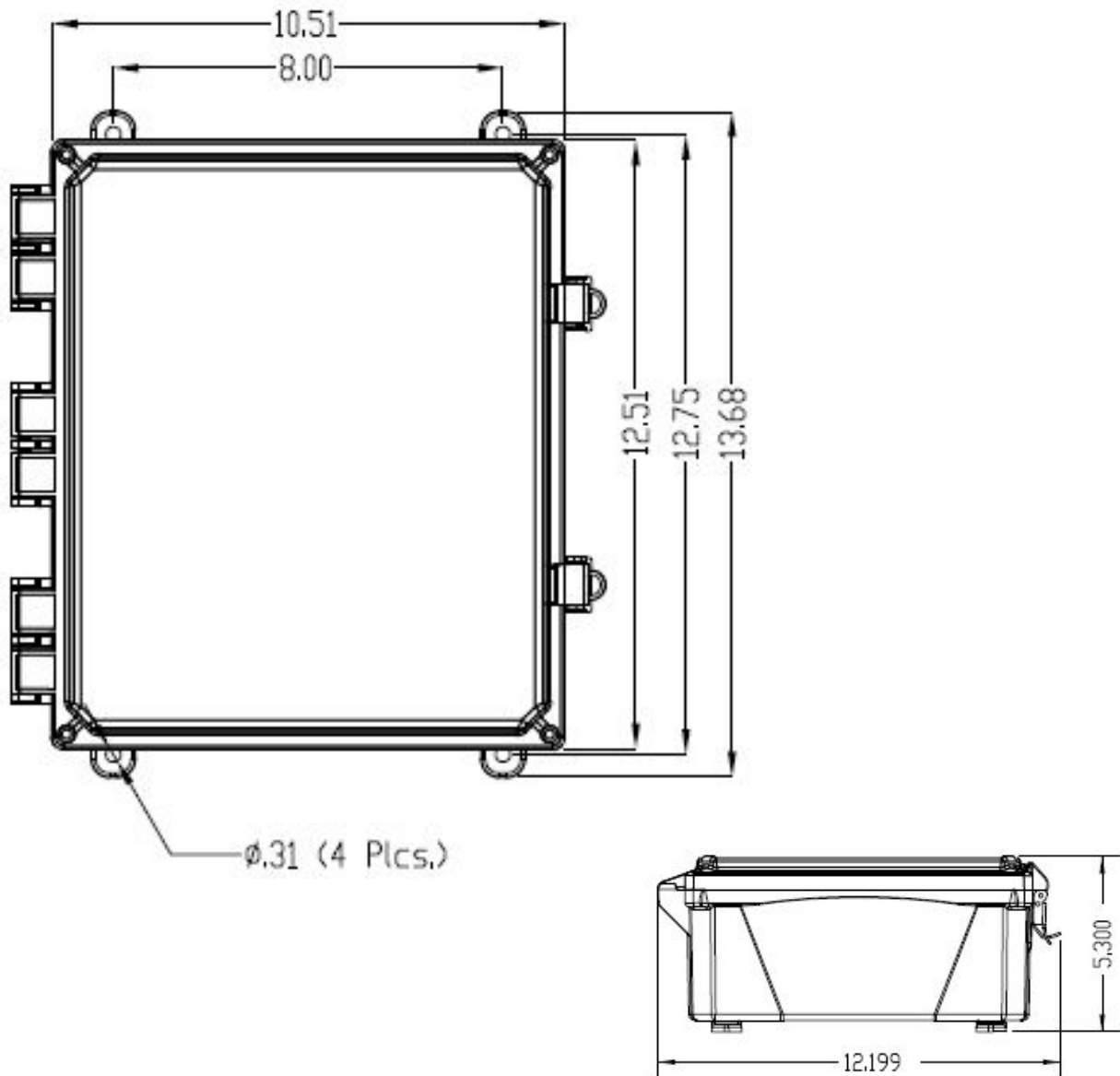



Building Entrance Terminal

OUTDOOR - 4000N SERIES - NEMA 4X

Fiberglass Enclosure

50 - 100 PAIR - OUTDOOR - NEMA 4X




Underwriters
Laboratories

Physical Dimensions

13.81 X 11.85 X 6.55

(H" x W" x D")

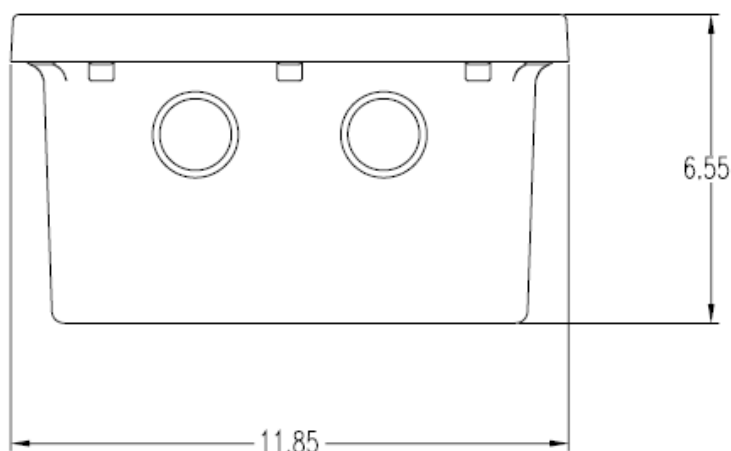



Building Entrance Terminal

OUTDOOR - 4000N SERIES - NEMA 4X



Underwriters
Laboratories

Metal Enclosure

4 - 25 PAIR - OUTDOOR - NEMA 4X

Physical Dimensions

14.00 X 10.00 X 6.18

(H" x W" x D")

